

P1521 Specification Sheet


Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

Ordering Guide

Example: P1521 8 A

Product Code	P1521		
Pole Height	8	8'	
	10	10'	
	12	12'	
	14	14'	
Finish	A	Black	*1
	B	White	
	G	Verde	*1
	H	Bronze	
	J	Green	

*1 Base Covers are composite material

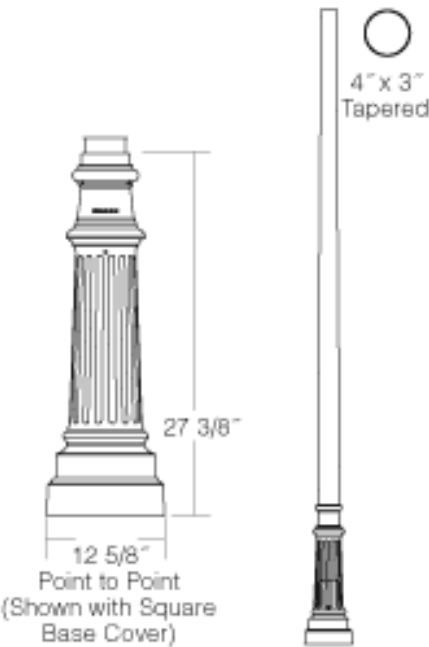

Specifications

HOUSING: 356 HM high-strength, low-copper, proprietary cast aluminum alloy . 6063-T6 Extruded aluminum . Anchor rods are hot dipped galvanized steel .
FINISH: A durable polyurethane enamel finish is applied after assemblies are shot blasted to create a surface profile which allows for the highest level of paint adhesion. Laboratory tested for superior weatherability and fade resistance in accordance with ASTM B-117-64 and ANSI/ASTM G53-77 specifications. For larger projects where a custom color is required, contact the factory for more information.
WARRANTY: Three-year limited warranty.
Tenon/Top: 3" OD
Bolt Circle: 9 3/8"
Anchor Rods: (4) 1/2" dia. x 15 1/2"
Base Dimensions: 8 1/4" sq. x 27 3/8"
Base Cover: (Included) 9" sq. x 3"
Hand Hole : 3" x 5"
Shaft: 4" to 3" Tapered
Wall Thickness:

P1521 Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

0.125 Aluminum

Wall Thickness:
0.188 Aluminum (14')

Height :
8', 10', 12', 14'

Pole EPA Values

Windspeed(mph)	Height			
	8'	10'	12'	14'
80	10.2400	8.1200	6.6400	7.5700
100	5.7800	4.4400	3.5000	4.2600