

# Linear Flush Mount

# LED

## 75 Watt 5500 Lumen Linear Flush Mount



The ETi 75watt 5500 lumen LED linear flush mount fixture offers exceptional performance for precision lighting applications, while reducing energy and maintenance costs when compared with conventional light sources. Lasting over 5 times longer, these flush mount fixtures are high quality replacements for fluorescent flush mount fixtures and available in 4000K. They are UL listed for use in damp and dry locations. Warranty 5 years. Suitable for installations from - 4° F to 113° F.


### KEY FEATURES & BENEFITS

- 75 Watt Low Power and High Performance
- 5500 lumens
- Dimmable
- 80 CRI , 4000K
- UL-Damp and Dry Locations
- Replaces most applications using 32w fluorescent lamps
- Rated life 50,000 hours



This light source meets restrictions on hazardous substances.

### FIXTURE DIMENSIONS

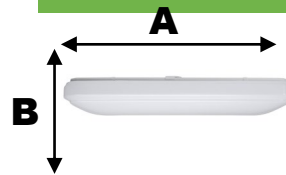

SKU# 54649142  
Dimension A = 49"  
Dimension B = 4"



This device complies with part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. For FCC Part 15 user information, please see [www.etiled.us/fcc15b](http://www.etiled.us/fcc15b)

### APPLICATION INFORMATION

Designed to be used anywhere a standard fluorescent fixture is used. Typically used in bedrooms, hallways, kitchens, living rooms and recreational rooms. Other applications apply in commercial, office, retail, restaurants, schools, hospitals and hotel/motel locations.



855-384-7754 [www.etissl.com](http://www.etissl.com)

# 75 Watt 5500lms Linear Flush Mount

# LED

## SPECIFICATION DATA

Project \_\_\_\_\_

Item Number \_\_\_\_\_

Prepared by \_\_\_\_\_ Date \_\_\_\_\_

## ORDERING INFORMATION

Item Number	Description	Wattage	Input Voltage (VAC)	Average Rated Life <sup>1</sup>	Typical Lumens <sup>2</sup>	CCT <sup>3</sup>	CRI <sup>4</sup>	Power Factor	R9	Duv	CBCP	Beam	Operating Frequency
54649142	Dimmable LED Ceiling Light	75	120	50,000	5500	4000K	80	>.9	45	.00060	1620	120	60Hz
<sup>1</sup> Hours lifetime with 70% lumen maintenance													
<sup>2</sup> Thermally stable typical lumens (±10%)													
<sup>3</sup> Thermally stable CCT (±10%)													
<sup>4</sup> Color rendering index/Ra													

## SHIPPING INFORMATION

Item UPC	Item Dimensions (H x L x W)	Item Weight (lbs)	Inner Pack Qty	Inner Carton Bar Code	Inner Carton Dimensions (H x L x W)	Inner Pack Weight (lbs)	Master Pack Qty	Master Carton Bar Code	Master Dimensions (H x L x W)	Master Pack Weight (lbs)
836607009425	4" x 49" x 17.5"	12	N/A	N/A	N/A	N/A	1	836607009425	6.75"x52"x20"	15

### ADA Compliant

Meets American with Disabilities Act standard extension requirements.



**The Americas Headquarters**  
**720 Corporate Woods PKWY**  
**Vernon Hills, Illinois 60061**

855-384-7754 [www.etissl.com](http://www.etissl.com)