
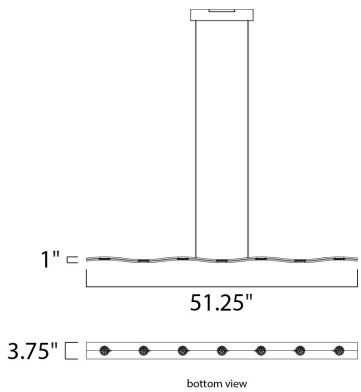


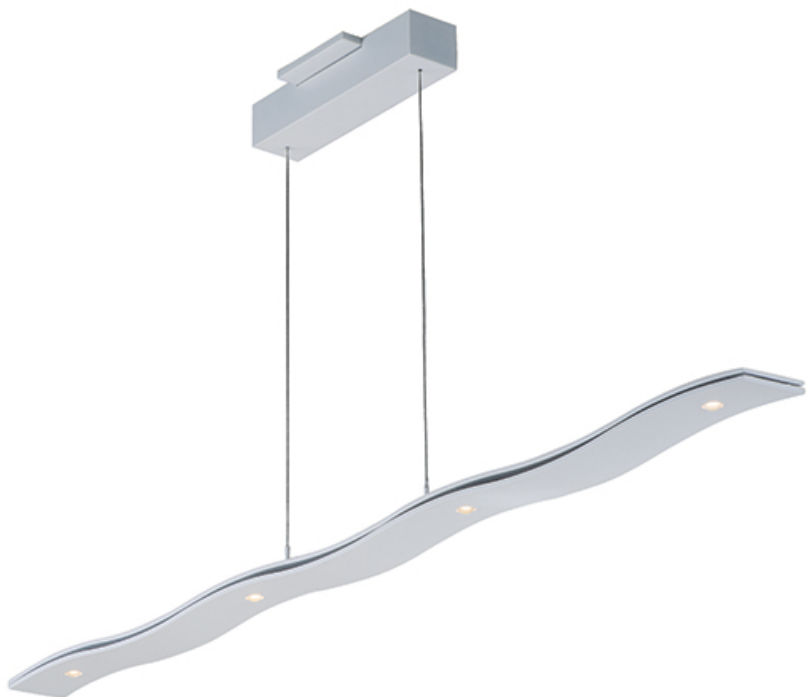

Measurements:

<u>Height</u>	<u>Width</u>	<u>Length</u>	
1.00"	4.75"	51.25"	
<u>Max OAH</u>	<u>Min OAH</u>		
121.00"	4.75"		
<u>Hanging Weight</u>	<u>Canopy Width</u>	<u>Canopy Height</u>	<u>Canopy Length</u>
8.80 lb	4.75"	2.25"	11.75"

Lamping:

LED PCB LED	2,450 Rated Lumens
1 35W PCB LED	3000 Color Temperature
35 total watt	80+ CRI
Dimmable : Standard Triac/Lutron® or Leviton® CL	

Shipping:

<u>Carton Weight</u>	<u>Carton Width</u>	<u>Carton Height</u>	<u>Carton Length</u>
12.30 lb	10.00"	4.70"	53.90"
<u>Master Pack Qty</u>	<u>UPC</u>	<u>UPS</u>	
1.0000	845094075516	Yes	

Finish:

Matte White MW

Material:

Aluminum

Certification:

Dry Location

Additional:

PCB LED (Included)
Adjustable



Contemporary
Lighting™

253 NORTH VINELAND AVE. | CITY OF INDUSTRY, CA 91746
T. 626.956.4200 | F. 626.956.4225

et2online.com
#ET2lighting

Always consult a qualified, licensed electrician before installation of any products...