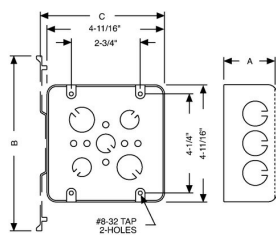


**4-11/16 IN. SQUARE WELDED BOXES 2-1/8 IN. WITH CONDUIT KO'S****4-11/16 in. Square Bracketed Boxes, 2-1/8 in. Deep - Welded with Conduit KO's
600V, Raised Ground, FM****A26**

Catalog #: 254

APPLICATIONS

RACO® 4-11/16" Boxes are used for a wide variety of industrial applications where larger sized conductors or wiring devices are needed and more volume is required
N/A

PRODUCT FEATURES

Reference the Box Selection section in the front of this catalog for complete description of bracket types and features
Combination screw heads provide for faster installation
TKO knockouts allow for design and installation flexibility

UL LISTED

File E195978

COMPLIANCES

600V Per UL 514-A, suitable for use without a bonding jumper in circuits up to 600 volts
MSDS
www.hubbell-rtb.com/certifications/Hubbell-RACO_MSDS_for_Steel_Boxes_and_Covers.pdf

GENERAL PRODUCT INFORMATION

Wiring System: Conduit
Country of Origin: USA

CONFIGURATION

Bracket Type: FM, for Metal or Wood Studs
Bracket Setback: 3/8 in.
Drawn or Welded: Welded
Raised Ground: Yes
Side Knockout(s): (9) TKO®
Bottom Knockouts(s): (1) 1/2 in. & (3) TKO®

DRAWING DIMENSIONS

Dimension A: 2-1/8 in.
Dimension B: 7-5/8 in.
Dimension C: 5-1/16 in.

PRODUCT MEASUREMENTS

Depth: 2-1/8 in.
Cubic Inches (cm3): 42.0 (688.2)
Wt. Ea. (Lbs.): 1.318
Product Length (in.): 2.19
Product Width (in.): 7.63
Product Height (in.): 5.06

PACKAGING

Minimum Pack Qty.: 25
Std. Pkg.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 131.80
Ship Carton Length (in.): 23.75
Ship Carton Width (in.): 7.75
Ship Carton Height (in.): 10.75
Ctn Weight (Lbs.): 32.95
Pallet Qty: 1200
UPC Number: 050169002544
I2of5: 30050169002545