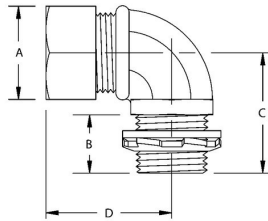


**90 DEGREE CONDUIT AND CORD CONNECTORS - STEEL/MALLEABLE IRON****90 Degree Connectors Steel/Malleable Iron**  
N/A**B48**

Catalog #: 3430

**APPLICATIONS**

For use in outdoor or indoor locations on flexible metallic liquidtight conduit and Type B flexible nonmetallic liquidtight conduit  
 Use to positively bond the conduit to a box or enclosure

**PRODUCT FEATURES**

RACO liquidtight connectors are suitable for use in Class I, Div. 2, Class II, Div. 1 & 2; and Class III, Div. 1 & 2 hazardous locations  
 Patented split gland-ring is designed to slip onto the conduit quickly gripping the jacket of the conduit, speeding installation, assuring a perfect seal, and preventing pullouts  
 All components are reusable - RACO liquidtight connectors may be easily disassembled and reused after years of service  
 Sealing washer (included) provides a liquidtight seal when terminating the connector in a threadless opening  
 Heavy duty locknut included with every RACO liquidtight connector assures continuity of ground  
 UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation  
 All steel/iron components are zinc electro plated for added corrosion protection  
 3/8 in. to 4 in. Malleable iron bodies  
 3/8 in. to 1 in Steel nuts, 1-1/4 in. to 4 in. Malleable iron nuts  
 N/A

**UL LISTED**

Standard 514B, UL Listed E195969

**CSA**

C22.2 No. 18

**GENERAL PRODUCT INFORMATION**

Sub Class: Uninsulated  
 Trade Size: 2-1/2 in.

**DRAWING DIMENSIONS**

Dimension A: 3-45/64 in.  
 Dimension B: 1-1/32 in.  
 Thread Spec. B: 2-1/2 in. - 8 NPT  
 Dimension C: 3-11/32 in.  
 Dimension D: 5 in.

**PACKAGING**

Package Type: Carton  
 Ship Carton Qty.: 1  
 Product UPC-A Labeled: No  
 Weight (Lbs. Per/C): 615.00  
 Ship Carton Length (in.): 9.69  
 Ship Carton Width (in.): 5.19  
 Ship Carton Height (in.): 4.06  
 Ctn Weight (Lbs.): 6.15  
 UPC Number: 050169034309  
 I2of5: 30050169034300