



Manually Operated Compression Tool

TYPE MT-25

Features



- ① • Dieless single indent compressor
- ② • Steel adjusting knob
- ③ • UL Listed terminals and splices
- ④ • Broad wire range

Benefits

- Reduces installed cost by having no separate dies to purchase, change or lose
- Provides fast and easy setting. Simply align the line on the die nest with the wire size gauge for proper crimping results.
- Ensures reliability. ILSCO's standard line of connectors are UL Listed when crimped with the MT-25 tool
- Covers a wire range of 8-250 MCM for copper connectors and 8-4/0 for aluminum connectors

Specifications

Length: 22.65"
 Weight: 6 lbs.
 Depth: 4.86"
 Width: 1.12"
 Conductor Range: 250MCM-8 CU
 4/0-8 AL

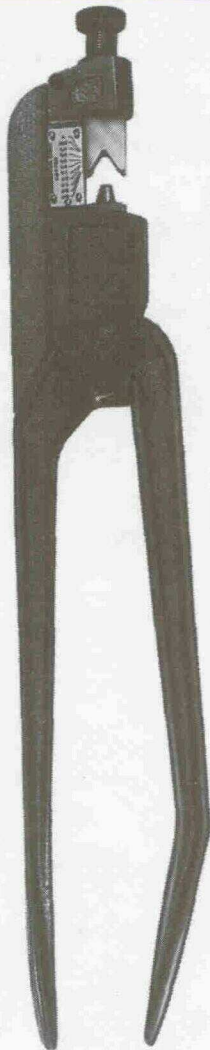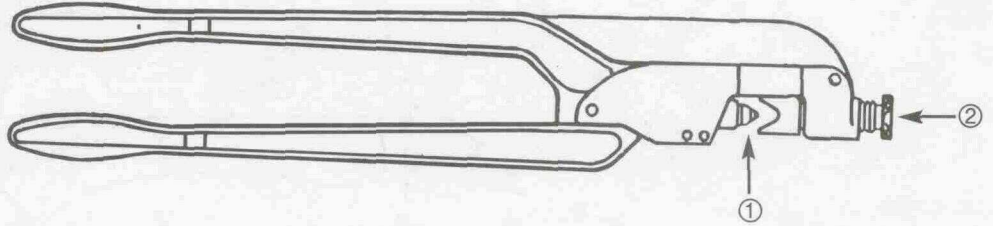

1

For Use with

Aluminum Connectors	Copper Connectors
ACL, ACN 4/0-8	CRA, CRB, CRC 250MCM-8
2ACL, 2ACN 4/0-8	CRA-L, CRB-L, CRC-L 250MCM-6
AS 4/0-8	CRA-L2, CRB-L2, CRC-L2 250MCM-6
	BT, BT-45, BT-90 250MCM-6
	CCL Series
	CCL Series
	CT 250MCM-8
	CTL 250MCM-6
	CCS Series

K