

InvisiLED® LITE

24V LED Tape Light

WAC LIGHTING

Responsible Lighting®

Tape Section



3 LED "L" Connector



Fixture Type:

Catalog Number:

Project:

Location:

PRODUCT DESCRIPTION

Professional grade white tape light that delivers optimal color consistency and brightness. An ideal system for task or accent lighting applications.

FEATURES

- Ultra thin profile at 3/8"
- Diodes spaced evenly at 1" on center
- Minimum run length of 1'
- May be field cut every 2" at the end of a run
- Three mounting methods provided for different surfaces
- Specially rated for installation in the storage area of a clothes closet
- 50,000 hour rated life
- 5 year WAC Lighting product warranty

SPECIFICATIONS

Construction: Flexible, silicone cased tape light. Peel and stick 3M construction adhesive on back. Indicating marks for field cutting.

Power Supply: Remote and plug-in electronic Class 2 transformers. 120 - 277VAC 50/60Hz input, 24V 60W and 96W output.

Light Source: 12 LEDs per foot. Runs on 24V at 2W per foot.

 
Dimming: May be dimmed with electronic low voltage (ELV) dimmer.

Operating Temperature: -4°F – 122°F (-20°C – 50°C), relative humidity 95%.

Standards: UL & CUL Listed for damp locations.

ORDER NUMBER – TAPE SECTIONS

Model	Watts/ft	Color Temp	CRI	Lumens/ft	Length	Qty	Tape Color
LED-T24 2	27L 2700K 85 135 30L 3000K 85 150				2IN 2 inches	1	WT White
					2IN10 2 inches	10	
					1 1 foot	1	
					1-40 1 foot	40	
					5 5 feet	1	




LED-T24____-____-WT

Example: LED-T2430L-2IN10-WT

ORDER NUMBER – 3 LED "L" CONNECTOR

Model	Watts/ft	Color Temp	CRI	Lumens	Tape Color
LED-T24	0.7	27L 2700K 85 38	85	38	3L-WT White
		30L 3000K 85 40	85	40	

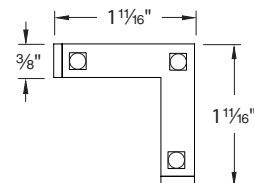

LED-T24____-3L-WT

Example: LED-T2427L-3L-WT

waclighting.com
Phone (800) 526.2588
Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive
Port Washington, NY 11050

Central Distribution Center
1600 Distribution Ct
Lithia Springs, GA 30122

Western Distribution Center
1750 Archibald Avenue
Ontario, CA 91760




InvisiLED® LITE

24V LED Tape Light













 

WAC LIGHTING

Responsible Lighting®

Class 2 Power Supply (Required)

Type		Model	Input	Output	Max Run	Dim	
Remote		EN-2460-RB2-T EN-24100-RB2-T	120VAC 120VAC	24VAC / 60W 24VAC / 96W	30 feet 40 feet	ELV ELV	Includes a 6 foot lead wire
Plug-in		EN-2460-P-AR-T EN-24100-P-AR-T	120VAC 120VAC	24VAC / 60W 24VAC / 96W	30 feet 40 feet	ELV ELV	Includes a 6 foot lead wire
Remote 277V		EN-24100-277-RB2-T	277VAC	24VDC / 96W	40 feet	0-10V	Includes a 6 foot lead wire

Accessories

Aluminum Channel		LED-T-CH	5 feet	Includes a diffuser, two end caps, and five screws		
Deep Aluminum Channel		LED-T-CH1	5 feet	Includes a diffuser, two end caps, and five screws		
45° Angled Aluminum Channel		LED-T-CH2	5 feet	Includes a diffuser, two end caps, and ten screws		
Fixed Angle Channel Clip		LED-T-CL3-PT	5 feet	Used to mount any aluminum channel Includes 2 pieces, 4 screws		
Adjustable Channel Clip		LED-T-CL2-PT	5 feet	Used to mount any aluminum channel Adjusts 50° from center either way Includes 2 pieces, 4 screws		
Retrofit Channel		LED-T-RC	3 feet	Creates fixed curves		
Clip		LED-T-CL	10 pcs	Holds the tape from the underside Includes 10 pieces, 10 screws		
Curve Clip		LED-T-CL1	10 pcs	Runs over the tape to secure the angled tape Includes 2 pieces, 4 screws		
Lead Wire		LED-TC-P-2 LED-TC-P-2-WT LED-TC-P-12 LED-TC-P-12-WT	Black White Black White	2 ft 2 ft 12 ft 12 ft	Alternative lengths for plug-in power supplies	
Extension Cable		LED-TC-EXT-144 LED-TC-EXT-144-WT	Black White	12 ft 12 ft	Extends distance between a hard wired power supply or wiring box to a tape section	
Low Voltage Wiring Box With Feed		LED-TC-B-2 LED-TC-B-2-WT	Black White	L: 1½" W: ¾" H: ⅞"	Neatly houses up to two wires with 12" female feed	
Low Voltage Wiring Box		LED-T-B	White	L: 1½" W: ¾" H: ⅞"	Neatly houses up to two wires	
Wiring Box With Switch		TB-S	White	L: 6¼" W: 1⅝" H: 1¼"	Use when spanning a large gap in a system layout without leaving exposed wiring	
Joiner Cable		LED-TC-IC2 LED-TC-IC6 LED-TC-IC12 LED-TC-IC36 LED-TC-IC72	Black Black Black Black Black		LED-TC-IC2-WT LED-TC-IC6-WT LED-TC-IC12-WT LED-TC-IC36-WT LED-TC-IC72-WT	White White White White White 2 in 6 in 12 in 36 in 72 in Connects tape sections
3-Way "Y" Connector		LED-TC-Y LED-TC-Y-WT	Black White	Connects tape sections		
4-Way "X" Connector		LED-TC-X LED-TC-X-WT	Black White	Connects tape sections		
"L" Connector		LED-TC-L LED-TC-L-WT	Black White	Connects tape sections		
End cap		LED-TC-EC LED-TC-EC-WT	Black White	1 cut end cap and 1 male end cap		
Male to male connector		LED-TC-MM	Black	50 Qty		