


# Composite Inground (IL136) Specification Sheet

|               |              |                    |
|---------------|--------------|--------------------|
| Project Name: | Location:    | MFG: Philips Hadco |
| Fixture Type: | Catalog No.: | Qty:               |

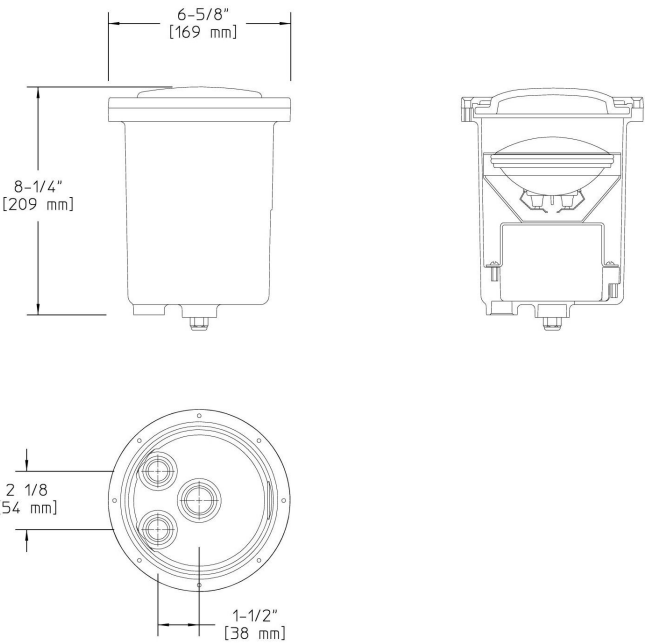

## Ordering Guide

Example: IL136 G H

|              |       |                    |
|--------------|-------|--------------------|
| Product Code | IL136 | Composite Inground |
| Rock Guard   | G     | Rock Guard *2      |
| Finish       | H     | Bronze             |
|              | N     | Natural Brass *1   |

\*1 Natural Cast Bronze

## Specifications

- HOUSING:**  
Single-piece compression molded fiberglass reinforced polyester composite, factory pressure tested to ensure water will not wick or leak through. Trim ring is a compression molded polyester.
- FINISH:**  
Composite is textured, pressure formed, molded-in-color.
- OPTICAL ASSEMBLY:**  
Lamps have 15° articulation either side of vertical and 358° rotation without interruption of beam pattern. Clear convex, tempered soda-lime glass for high impact resistance. 2,200-pound live-load rated, standard walk-over lens.
- LAMPING:**  
75W maximum PAR 36/AR11 screw terminal lamp. Lower wattage lamps are acceptable.
- ELECTRICAL ASSEMBLY:**  
Double screw terminal socket. 12 Volt fixture is pre-wired with 3-ft pigtail of 18-2 AWG, 105° C, SPT-1W wire. Low voltage quick connector, catalog #LVC3 included for easy hook-up to the low voltage supply cable, not included. 12 Volt system requires remote transformer, not included.
- WARRANTY:**  
Three-year limited warranty.
- CERTIFICATIONS:**  
ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards. ADA Compliant when flush mounted with CP2 or CPS2.
- Height :**  
8 7/16" (214mm)
- Width:**  
6 5/8" (169mm)
- Max. Weight:**  
3.5 lb