


Mounting

MSLL  
MSLL-BRACKET

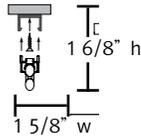

\*ships w/ fixture



Product Features

- High efficiency built-in program start ballast
- End of Lamp Life (EOL) protection
- Low profile rigid extruded aluminum body
- Quick connection system
- Daisy chain up to 600W together

Specification

- Frequency range: 60Hz
- Voltage: 110 -130V  
277V\* HE only
- Power factor: > 97%
- Color Rendering Index (CRI) = Ra > 80
- Lamp life: 20,000hr
- Tube diameter: 16mm(T5)
- Class of protection: I
- Degree of protection: IP20
- Operating Temperature: 0-45 °C  
32-113 °F

Warranty

3 year warranty

Certifications



Beam Angle

270° = NSLL

Notice

Max connection : 600W  
14W HE (42 pcs), 21W HE (28 pcs),  
28W HE (21 pcs), 24W HO (25 pcs),  
39W HO (15 pcs), 54W HO (11 pcs)

Finish

White powder coated finish (Standard)

Weight

NSLL 14/24W = 1.0 lbs.  
NSLL 21/39W = 1.2 lbs.  
NSLL 28/54W = 1.6 lbs.

Shipment

SlimLine Kits (fixture, lamps, options)  
do NOT ship assembled

POWER SUPPLY & ACCESSORIES (PS)  
Maximum run length 600W. It can be  
powered by standard 120V cord and  
plug or Feelux supplied metal hard  
wire box

DIMMING  
Refer to DimStimLine Data Sheets (DSSL)

MODEL NO.

- NSLL\_14W = HE 14W Length 22 7/8" (582 mm)\*
- NSLL\_21W = HE 21W Length 34 11/16" (882 mm)\*
- NSLL\_28W = HE 28W Length 46 4/8" (1182 mm)\*
- NSLL\_24W = HO 24W Length 22 7/8" (582 mm)
- NSLL\_39W = HO 39W Length 34 11/16" (882 mm)
- NSLL\_54W = HO 54W Length 46 4/8" (1182 mm)

COLOR / K

- 22K = 2200K
- 24K = 2400K
- 27K = 2700K
- 30K = 3000K
- 35K = 3500K
- 40K = 4000K
- 65K = 6500K
- 80K = 8000K

VOLTAGE

- 120V = 120 volts
- 277V = 277 volts\* (only available in HE)

OPTIONS

- C = Cover (Polycarbonate diffuser)
- SLL14CV = Cover for 4/24W
- SLL21CV = Cover for 21/39W
- SLL28CV = Cover for 28/54W

Accessories

CONNECTORS

- \_\_SLLCPL/XL = Direct connecting cap
- \_\_SLL-OUTLET CAP = Protecting cap for termination

Connecting Cable from fixture to fixture...

- \_\_SLLPTC/XL = Connecting cable 6" (150mm)
- \_\_SLLPTC1/XL = Connecting cable 1' (300mm)
- \_\_SLLPTC2/XL = Connecting cable 2' (600mm)
- \_\_SLLPTC4/XL = Connecting cable 4' (1200mm)
- \_\_SLLPTC6/XL = Connecting cable 6' (1800mm)

Connecting Cable from Metal Hard Wire Box (MHWB) to first fixture...

- \_\_ESLSLLPTC/XL = Connecting cable 6" (150mm)
- \_\_ESLSLLPTC1/XL = Connecting cable 1' (300mm)
- \_\_ESLSLLPTC2/XL = Connecting cable 2' (600mm)
- \_\_ESLSLLPTC4/XL = Connecting cable 4' (1200mm)
- \_\_ESLSLLPTC6/XL = Connecting cable 6' (1800mm)

POWER CORD

- \_\_SLLPC120/XL = Power cord 6' (1800mm) with plug
- \_\_MHWB/DSL = Metal hard wire box

Other connector lengths available upon request

PRODUCT SPECIFICATION EXAMPLE:

NSLL_14W	22K	120V	C	STD	
MODEL	COLOR/K	VOLTAGE	OPTIONS	FINISH	REQUIRED POWER SUPPLY & ACCESSORIES*