



BR/R LED

8BR30/LED/850/DIM 120V 6/1

8BR30/LED/850/DIM 120V

Philips Dimmable LED Reflector Lamps provide a soft, diffused level of light and smooth dimming to reduce glare. The sleek, lightweight design is ideal for downlighting.

Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Bulb Shape	BR30 (BR30)
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000X
Technical Type	8-65W
Light Technical	
Color Code	850 [CCT of 5000K (2)]
Initial lumen (Nom)	650 lm
Luminous Flux (Rated) (Nom)	650 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	82 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8 W

Lamp Current (Nom)	82 mA
Wattage Equivalent	65 W
Starting Time (Nom)	0.5 s
Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.8
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	76 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Frosted (FR)
Approval and Application	
Suitable For Accent Lighting	Yes
Energy Consumption kWh/1000 h	8 kWh


BR/R LED

Product Data

Order product name	8BR30/LED/850/DIM 120V
EAN/UPC - Product	046677458065
Order code	458067
Numerator - Quantity Per Pack	1

Numerator - Packs per outer box	6
Material Nr. (12NC)	929001155604
Net Weight (Piece)	0.001 kg

Dimensional drawing

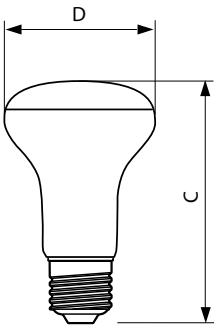

BR30 G5 120V 8.0W-65W 650lm 5000K E26 D

Product	D	C
8BR30/LED/850/DIM 120V	96 mm	132 mm

Photometric data

