




Catalog Number 73120
UPC Number
Description Emergency Light Incandescent Side Light



Features

- Completely Self-Contained
- Fully Automatic Operation
- Compact, Low Profile Designs in Neutral Finish
- Push to Test Switch
- 6-Volt, Pure Lead, Maintenance Free Battery
- Environmental Coated, Solid State Charger
- 2 x 5.4 Watt Incandescent Lamps
- Automatic, Low Voltage Disconnect (LVD)
- Universal Transformer for 120 or 277 VAC
- Replacement bulb GE 939 or equal
- Universal Mounting Plate
- Injection Molded, V-O Flame Retardant, High Impact, Thermoplastic Housing
- Charge Rate/Power on LED Indicator Light
- 90 Minute Emergency Operation
- ETL Rated Damp Location
- Self Diagnostic Self Test Feature
 - Identifies Battery Disconnection, Testing & Failure
 - Self Testing and 15 Minute Discharge Every 30 Days
 - Self Testing and 90 Minute Discharge Once Per Year

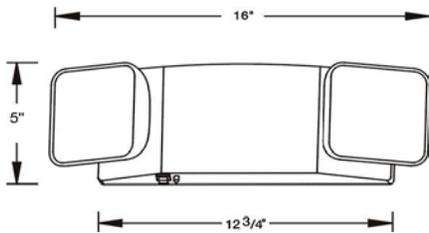

Dimension Information

L Inches (mm)	12.75
H Inches (mm)	5.00
Depth Inches (mm)	4.00

Specifications

Input Rating Amps:	0.06
Input Rating Watts:	6.7 @ 120V 7.3 @ 277V
Output Load:	10.8W Integral
Lamp Type:	5.4W Incandescent
Voltage Rating:	120/277
Flammability Rating:	UL94V-0
Battery Operation:	Lead Acid - 90 Minutes Minimum

Packaging

Box Qty	1
Master Carton Qty	6

Certifications

UL	UL 924
cUL	No
RoHS	Yes