

JOB NAME \_\_\_\_\_

JOB TYPE \_\_\_\_\_

COMMENTS \_\_\_\_\_

## DUNCAN RBZ

### 3604-L RBZ-RBZ

UPC: 844375025271



- 1 Light Pendant with Rod - Contemporary Style with industrial feel
- Simple, classic silhouette
- Fixture body is a warm, Rubbed Bronze finish
- Shade is in a warm, Rubbed Bronze finish

Fixture Finish:	Rubbed Bronze	
Glass/Shade Finish:	Rubbed Bronze	
Materials:	Steel, Glass	
Fixture Dimensions:	14"W x 14.125"H (Min: 22.875" - Max: 58.875")	35.56cmW x 35.88cmH (Min: 58.1cm - Max: 149.55cm)
Weight:	6.6 LBS	
Glass/Shade Dimensions:	13.75"Dia x 7.125"H	34.93cm Dia x 18.1cmH
Canopy Backplate Dimensions:	4.875"Dia x 1"E	12.39cm Dia x 2.54cmE
Chain/Rod/Wire Dimensions:	NA / 1ea 6", 3ea 12" / 10'	NA / 1ea 15.24cm, 3ea 30.48cm / 3.05m
Bulb Type:	Incandescent, Type A	No
Wattage:	1 x 100W(M)	
Voltage:	110V	
Install Position:		
Approved Location:	Dry Location	
Safety Rating:	UL,CUL	


### Also Available



3602-L RBZ-RBZ



3604-S RBZ-RBZ

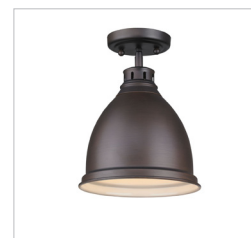

3602-FM RBZ-RBZ