

GFWT2-HGI



Color:



Ivory

UPC Code: 07847772625

Country of Origin: China

NEMA: 5-20R



Tamper Resistant Receptacles

Brand Features

Peace of mind, all the time. The SmartlockPro Self-Test GFCI tests itself even if you forget. Designed to meet the latest UL standard for auto-monitoring (self-test) our complete line of self-test GFCIs periodically conduct an automatic internal test to confirm that it can respond to a ground fault. With the slimmest profile on the market, the device allows for fast and easy installation, while Leviton's patented reset lockout mechanism prevents reset of the GFCI if it is not wired or operating correctly. The SmartlockPro Self-Test GFCI is the smart choice in ground fault circuit interrupter protection.

Item Description

20 Amp, 125 Volt, SmartlockPro Self-Test GFCI Duplex Receptacle , NEMA 5-20R, 2P, 3W, Extra-Heavy Duty Hospital Grade, Weather & Tamper-Resistant, 20A Feed-Through, Back or Side Wired - WHITE

Technical Information

AC Horsepower Ratings

At Rated Voltage: 1 HP

Electrical Specifications

Grounding: Self-Grounding Clip

Pole: 2

Wire: 3

Short Circuit Current Rating: 10kA

Environmental Specifications

Flammability: Rated V-0 per UL94

Operating Temperature: -35C to +66C

Material Specifications

Shutter Mechanism: Delrin® Acetal

Face Material: PBT

Body Material: Polycarbonate

Terminal Screws: Stainless Steel

Terminal Clamp: Brass

Line Contacts: Brass

Grounding Screw: Stainless Steel

Strap Material: Nickel Plated Steel

Ground Clips: Brass

Mechanical Specifications

Terminal ID: Black-Hot, White-Neutral, Green-Ground

Terminal Accom.: 14-10 AWG solid or stranded

Product ID: Ratings are permanently marked on device

Product Features

Color: Ivory

NEMA: 5-20R

Standards and Certifications

NEMA: WD-1 & WD-6



ANSI: C-73

Certification/Listing: UL, CSA, NOM-ANCE

Applicable Standards: UL 943, UL 498, CSA C22.2 No. 42 & 144, FedSpec W-C-596

Warranty

Product Warranty: 2-Year Limited

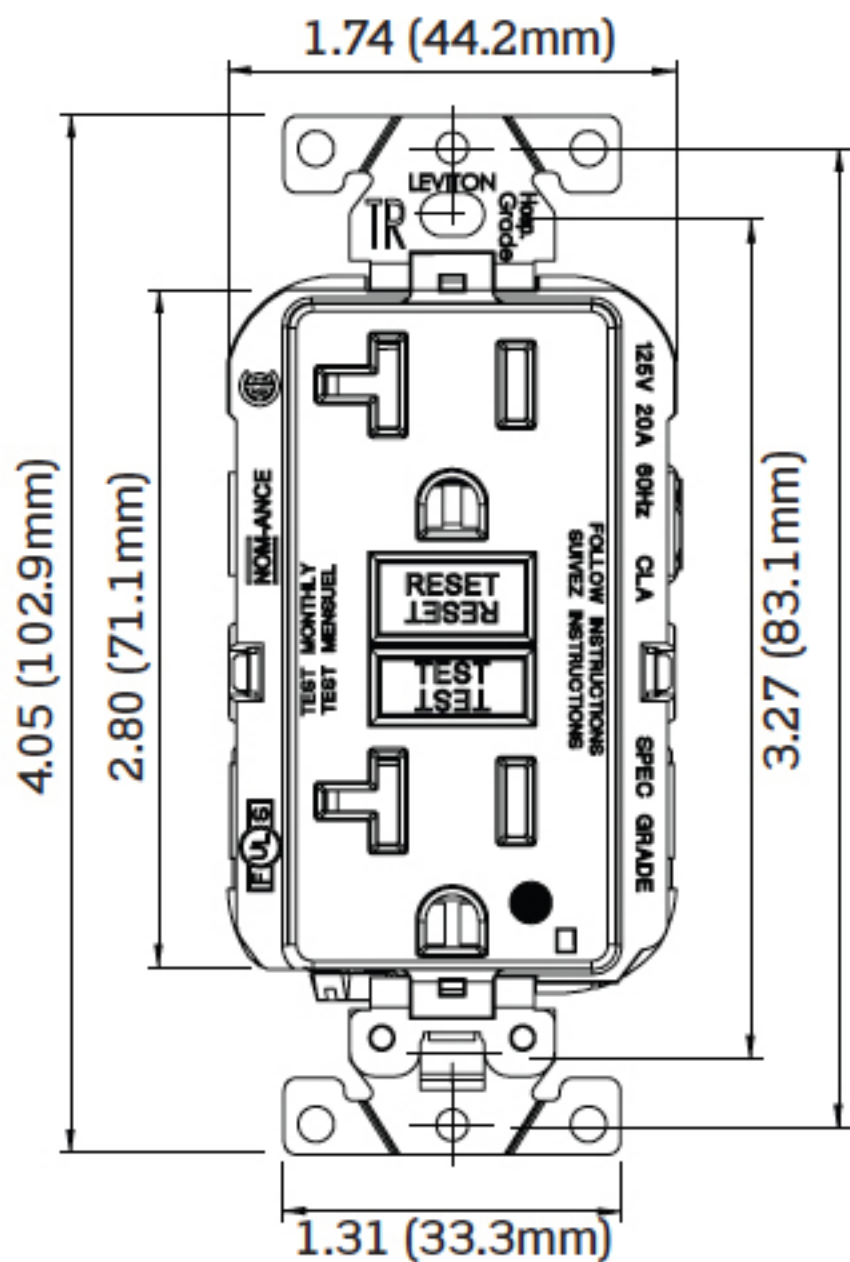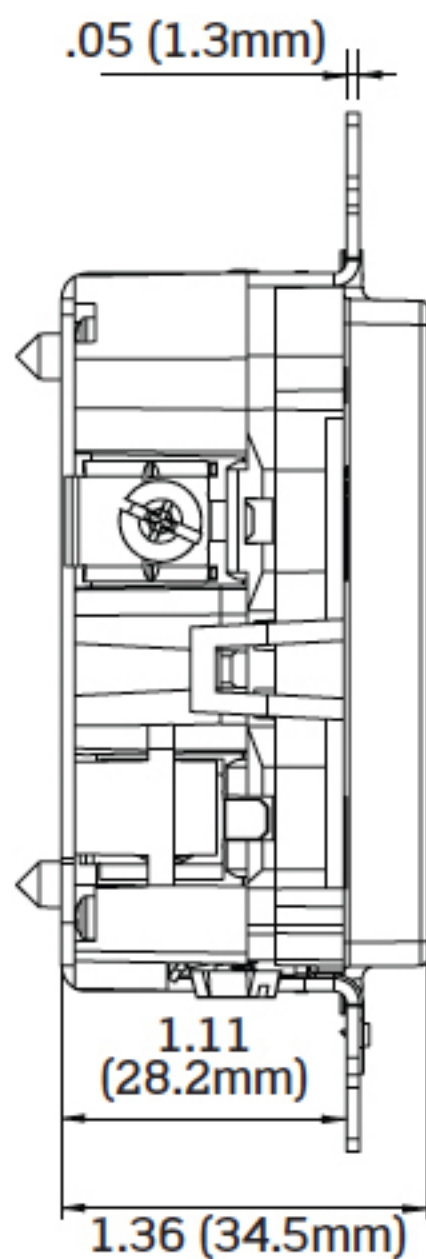

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: 1-800-323-8920 · FAX: 1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): 1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: 1-800-469-7890 ·

FAX: 1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2012-2016 Leviton Manufacturing Co., Inc. All rights reserved. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to: www.leviton.com/international/contacts/

