


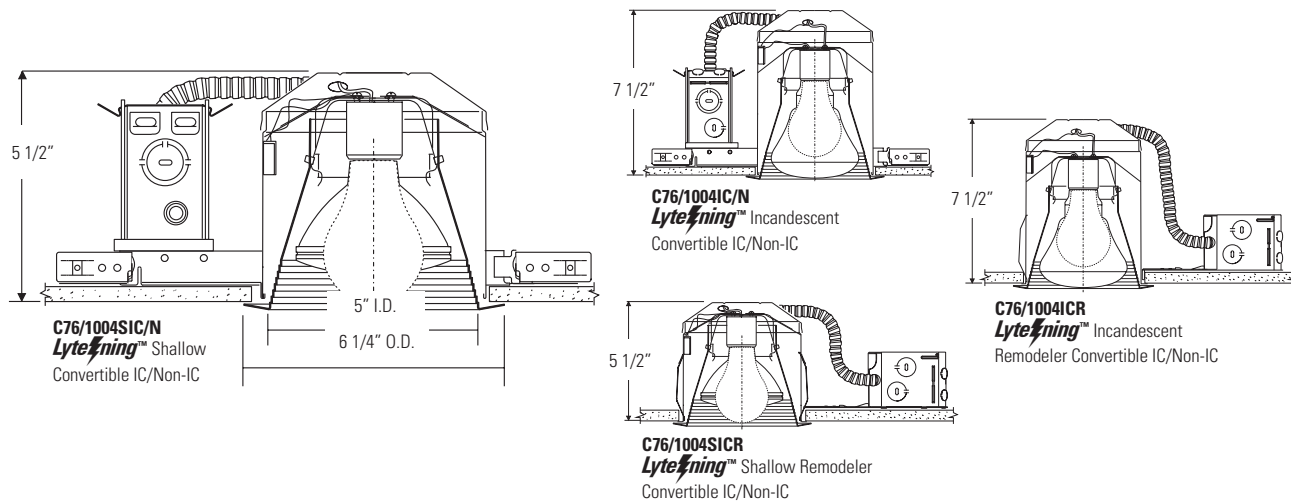

Complete Fixture consists of reflector Trim & Frame-In Kit. Select each separately.

Reflector Trim		Frame-In Kit — See Individual Frame-In Kit Specification Sheets							
		Incandescent				Fluorescent			
		Frame-In Kit	Installation Type	Lamping	Height	Frame-In Kit	Installation Type	Lamping	Height
C71 White Splay C71CD Clear Diffuse C71CL Specular Clear C71GD Specular Gold C76 Black Baffle C76WH White Baffle		1004IC/N*	IC		7 1/2"	1001F13U Series	Uniframe™ Non-IC	(1)Triple 13W (GX24q-1)	5 15/16" max.
		1004ICR*	IC Remodeler	50W PAR30	7 1/2"	1001F18U Series	Uniframe™ Non-IC	(1)Triple 18W (GX24q-2)	5 15/16" max.
		1004SIC	IC	65W BR30*	5 1/2"				
		1004SICR	IC Remodeler		5 1/2"	1001F13ICU/N	Performance IC	(1) Triple 13W (GX24q-1)	7 1/4"
		1004IC/N	Non-IC	75W PAR30	7 1/2"	1001F18ICU/N	Performance IC	(1) Triple 18W (GX24q-2)	7 1/4"
		1004ICR	Non-IC Remodeler	65W BR30	7 1/2"				
		1004SIC	Non-IC	75W PAR30	5 1/2"	1004F13 Series**	IC	(1) Quad/Triple 13W (GX24q-2)	7 1/2"
		1004SICR	Non-IC Remodeler	65W BR30	5 1/2"				
						1004F18 Series**	IC	(1) Triple 18W (GX24q-2)	7 1/2"
						1004F26 Series**	IC	(1) Triple 26W (GX24q-2)	7 1/2"

*Lower slot position.

**Upper slot position.

Features

- Reflector Trims:** Spun aluminum, .032" minimum thickness (#22 ga.)
Baffles: Matte black or gloss white painted baffle section, with gloss white flange.
Splay: Gloss white reflector and flange.
Reflectors: Polished, anodized, and sealed gold, diffuse, or clear with gloss white flange.
- Frame-In Kit:** Use only with Frame-In Kits shown above. See Frame-In Kit Specification Sheets for more details.

Labels

UL (Suitable for Damp Locations), I.B.E.W.

US and Foreign Patents Pending.

Job Information

Type:

Job Name:

Cat. No.:

Lamp(s):

Notes:

631 Airport Road, Fall River, MA 02720 • (508) 679-8131 • Fax (508) 674-4710
 We reserve the right to change details of design, materials and finish.
 www.lightolier.com © 2008 Philips Group • H0908