



Features:

Die-cast (grade of aluminum) Aluminum with tempered glass lens, utilizing stainless steel hardware.


- Citizen® COB LED's and YG® driver technology
- Dimming option available
- Precision die cast
- IP66 rated fixture for outdoor use
- Chip and fade resistant powder coat finish in any color
- Industrial grade, Standard button Photocell
- 6X6 beam angle standard, 3X3 spot-optics available in higher wattages
- Multiple mounting configurations to fit any application
- NOT AVAILABLE FOR CANADIAN MARKET

PROJECT INFORMATION:	
JOB NAME:	
FIXTURE TYPE:	
ITEM NUMBER:	
APPROVED BY:	

Specifications:

CCT	3500K
LED WATTAGE	100
SYSTEM WATTAGE	114
REPLACES (MH)	320
CRI	70
LPW	103
LUMENS	11717

Dimensions:

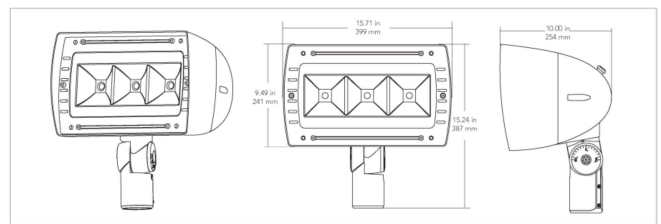

*In stock/quickship standard with 120V button photocell with cover cap and standard bronze finish. All dimmable SPI surge protector.
 **Lighting replacement wattage shown is an estimate only. All application data must be reviewed by a lighting designer, electrical engineer or application specialist to confirm photometry/luminance levels prior to installation for these replacement applications.



QUICK SHIP

*Quickship Medinah products come standard 4000K, 120V button photocell and cover cap and bronze finish. All dimmable SP1 surge protector.



CUSTOMIZATION OPTIONS


FLL400-114W					
MEDINAH FIXTURE MODEL	INDUSTRY WATTAGE	CCT	ELECTRICAL ACCESORIES	VOLTAGE	HOUSING COLOR
Customized orders may take approximately 8 weeks. Minimum quantity may apply to custom orders, contact sales for details.	100	3500K	PC = PhotoCell NA = None	V1 = 120V V2 = 208V V3 = 220V V4 = 240V V5 = 277V V8 = 120-277V	BZ = Bronze BK = Black SL = Silver WH = White GY = Gray

SAMPLE ORDER NUMBER:





Photometry:

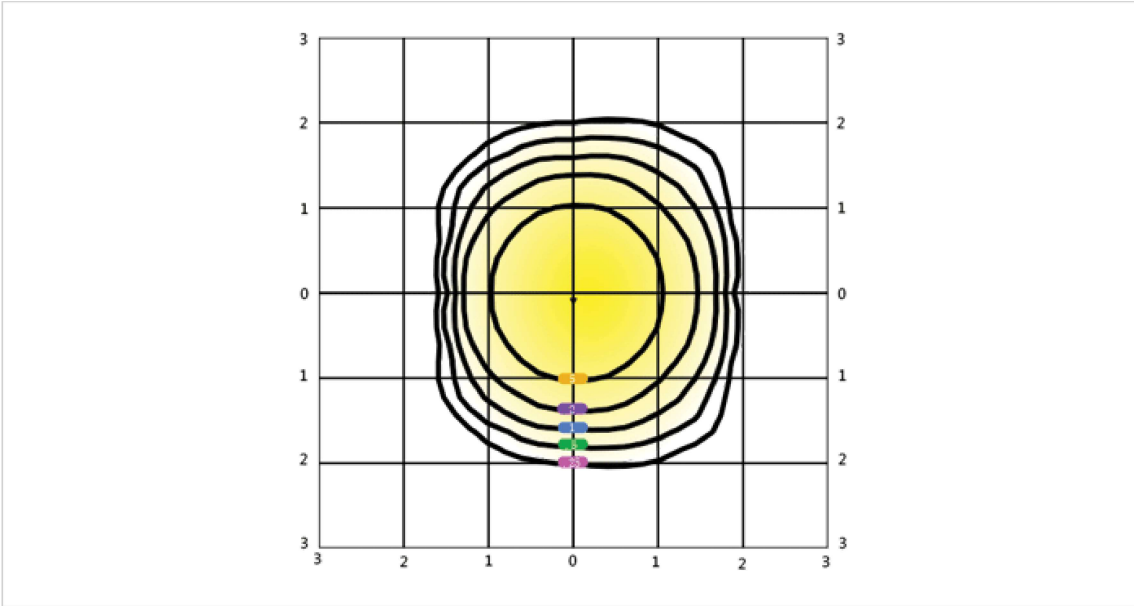

Warranty:

LUMINAIRE WARRANTY

Please contact us at info@medinahpower.com or at 1-844-870-LEDS to submit your warranty claim. Please have proof of purchase (receipt or invoice) when placing a claim. When properly installed and maintained under normal conditions of use Medinah warrants products to be free from defects in material and workmanship for the period stated below from the date of sale from an authorized dealer or reseller.

LED 5 years/50000 hours*

*LED failure is defined as having 10% of LEDs not being illuminated OR 30% total lumen loss.

Medinah does not assume any responsibility for damage to people, property, apparatus or otherwise resulting from improper installation or maintenance of its products. Warranty coverage shall not apply to any equipment of another manufacturer used in conjunction with Medinah products. Warranty does not apply to damages caused by improper installation, abuse, fire or acts of God. Medinah's only obligation under this limited warranty is to repair or replace any defective parts or products, at its discretion, providing such defective parts or products are brought to the attention of Medinah or place of purchase within the specified warranty time period and claim is made in writing within thirty (30) days of discovery. Medinah may repair or replace any Product(s) covered by this warranty at its sole discretion and in accordance with its procedure. The exclusive remedy for warranty claims shall be to furnish parts of products to replace defective items.

Any unauthorized return, repair, replacement or modification of the Product(s) shall void this warranty. This warranty applies only to proper use of the Product(s) as intended by Medinah and does not cover any misapplication or misuse of said Product(s), or installation in hazardous or corrosive environments or areas with other than normal temperatures and environmental conditions per application specifications. All other warranties, expressed or implied, including warranties of merchantability or warranties of fitness for any particular purpose we hereby disclaim.

Medinah Power | 12065 Clark Street Santa Fe Springs, CA 90670
1.844.870.LEDS | www.medinahpower.com