



F32T8/850/ES-25W

Std. Pack Qty.	25
Order Code	85025

PRODUCT SPECIFICATION

FLUORESCENT LAMPS



GENERAL CHARACTERISTICS

Lamp Type	Linear
Bulb	T8
Base	G13
Watts	25
Rated Avg. Life (hrs)	
3 hours per start	30000
12 hours per start	36000

DIMENSIONS

Normal Overall Length (inches) (C)	47.77
Normal Bulb Diameter (inches) (D)	1.02
Face to End of Opposing End (inches))	
Max. (B)	47.50
Min. (B)	47.41

Spectral Power Distribution

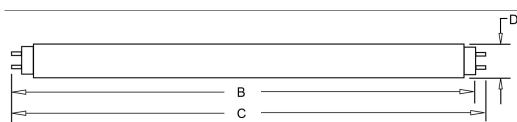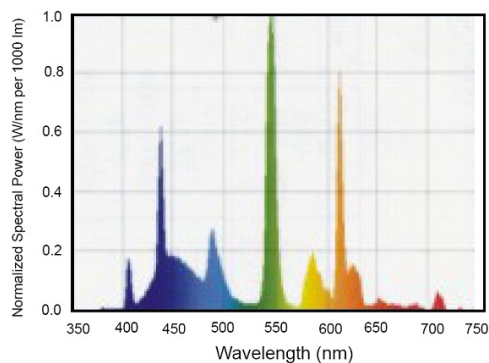

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	2400
Mean Lumens	2330
Color Temperature	5000 K
Color Rendering Index (CRI)	85


ELECTRICAL CHARACTERISTICS

Min. Starting Temperature (C)	10
Min. Cathode Resistance Ratio (Rh/Rc)	4.25
Max. Cathode Resistance Ratio (Rh/Rc)	6.5
Max. Current Crest Factor	1.7

Features

-

Lamp Mortality

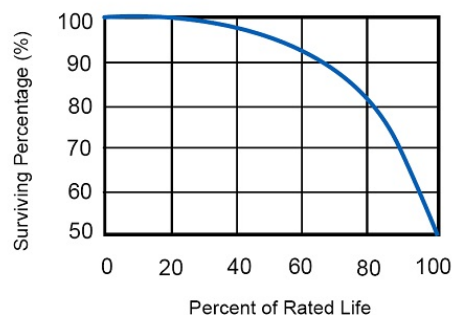

Lumen Maintenance

