



1/17/2012

**T8 Linear Fluorescent Lamp
17 Watt / 83 CRI / 4100K**

Project:	
Catalog#:	
Approved by:	

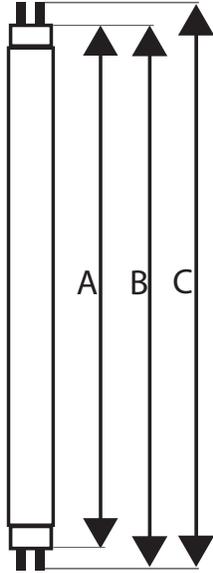

Ordering Information	
Howard Catalog Number (Ordering Code)	F17T8/841
UPC Code	02245
Description	T8 Low Mercury Linear Fluorescent
Package Quantity	25
Physical Characteristics	
Base	Medium Bipin
Bulb Type	T8 (8/8 inch)
Bulb Description	Tubular Fluorescent Lamp
Nominal Length (in)	24
Base face to base face (Amax) (in)	23.61
Base face to end of opposite base pin (Bmin/Bmax) (in)	23.70/23.89
End of base pin to end of the opposite pin end (Cmin/Cmax) (in)	23.84/23.89
Operating Characteristics	
Nominal Wattage	17
Approximate Initial Lumen (lm)	1400
Approximate Mean Lumen (lm)	1275
Average Rated Life (hours)	24000
Color Temperature (K)	4100
Color Rendering Index (CRI)	83

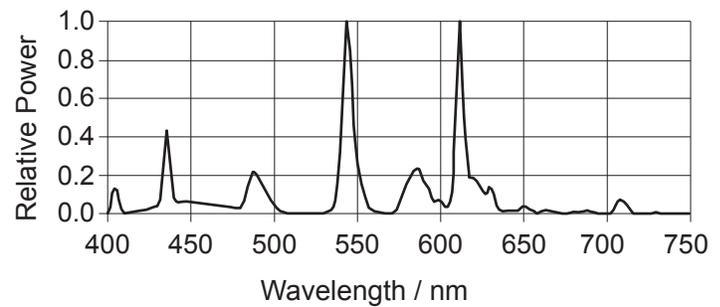

Note: Rated lamp life is 24,000 hours based on 3 hours per start and 30,000 hours based on 12 hours per start. Lamp life will be affected when using occupancy sensors, dimmers, or dimming systems. These products are Low-Mercury fluorescent lamps and pass the Federal TCLP for hazardous waste. Disposal regulations may vary; check local and state regulations. Specifications subject to change.

Specifications subject to change without notice.