




RIGID BODIES AND ASSEMBLIES

C Assembly

C13

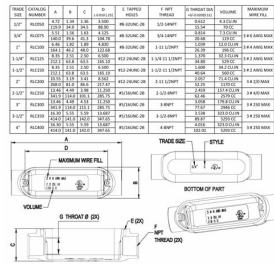

Catalog #: RLC150

APPLICATIONS

For use with threaded rigid/IMC conduit for pulling access or to split a run into multiple directions. Removable cover allows access for maintenance and making taps and splices to conductors.
N/A

PRODUCT FEATURES

- Durable die cast aluminum construction
- Premium powder coat finish
- Includes NBR synthetic rubber gasket
- Stamped aluminum cover
- Combination head screw

UL LISTED

File E331564

NEMA

NEMA 3R rated

NEC

2014 NEC® compliant

GENERAL PRODUCT INFORMATION

Trade Size: 1-1/2 in.

DRAWING DIMENSIONS

Dimension A: 8.35 in.
Dimension B: 2.51 in.
Dimension C: 2.50 in.
Dimension D: 6.50 in.
Dimension E: Tapped holes #12-24UNC-2B
Thread Spec. F: 1-1/2 - 11 1/2NPT
Dimension G: 1.600 in.

PRODUCT MEASUREMENTS

Cubic Inches (cm3): 30.8 (504)

PACKAGING

Package Type: Carton
Ship Carton Qty.: 2
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 110.00
Ship Carton Length (in.): 8.88
Ship Carton Width (in.): 4.00
Ship Carton Height (in.): 6.25
Ctn Weight (Lbs.): 2.20
UPC Number: 092326213165
I2of5: 30092326213166