


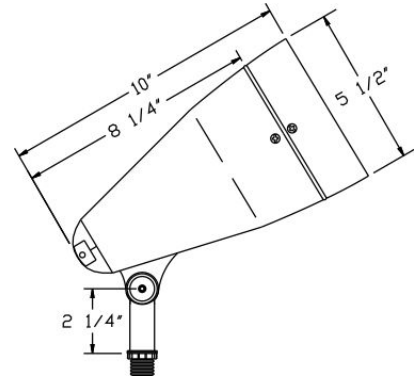


**Catalog#: HL38**  
**PAR38 BULLET WITH GLASS HOOD**

**Category** Line Voltage  
**Page** [H6](#)

**Specifications:**

Material	Cast Aluminum
Socket	Premium Grade Porcelain socket with Nickel contacts and Teflon-jacketed wire leads
Gasket	Sealed with High Grade Weatherproof Silicone Gasket
Wiring	Pre-wired with 24" SPT-1 Cord
Voltage	120 Volts
Lamp type	PAR38 Lamp Not Included, 90W Max.
Lens type	Tempered Glass Lens
Accessories	O-Ring Silicone Gasket Optional Glare Shield [ <a href="#">38V</a> ]
Certification	



Cat. No.	Finishes	UPC
HL38-BK	Black	615624266819
HL38-BR	Bronze	615624266826
HL38-GN	Green	615624266833
HL38-WH	White	615624266840
HL38-SA	Sand	615624373487

