




Email [Customer Service](#)  
or Call [\(800\) 992-3833](#)

## BN30369-UL Low Voltage Enclosure

### *Exterior Surface Mounted Enclosure*

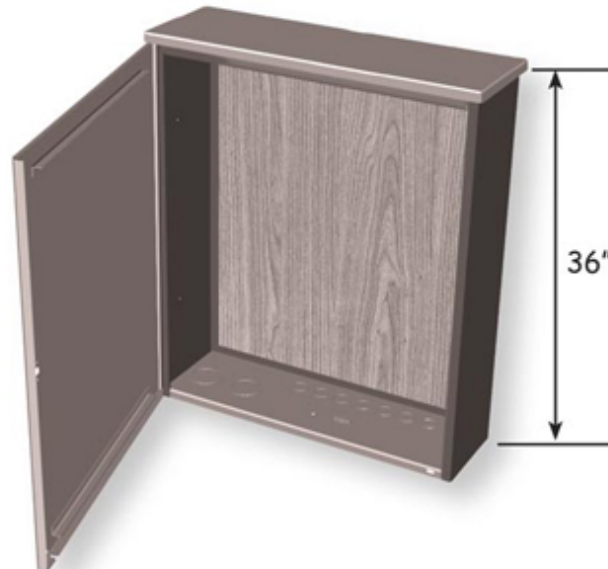

#### **Specification: BN30369W-UL Low Voltage Enclosure**

##### ***Exterior Surface Mounted Enclosure***


***30" Wide x 36" Tall x 9"***

***Deep Weight: 105 lbs.***

This enclosure is made of 14-gauge zinc-coated fabricated steel with a hinged door. Both are powder coated with a tan finish. This surface mounted service box is fully enclosed. The door is embossed with the word "Communication". It also includes a 3/4" plywood backboard for easy mounting of low-voltage utility equipment and a 4-position #4-14 wire ground bar mounted inside. The BN30369W-UL is UL listed (UL1863) and designed to NEMA 3R Specifications. The reinforced hinged door fastens with a standard 7/16" con or socket wrench.

This enclosure is nailed or screwed to an existing surface. This enclosure includes 2 bottom knockouts 2-1/2" to 3-1/2" (for 2" to 3" conduit) and 8 bottom knockouts 1-3/8" to 1-3/4" (for 1" to 1-1/2" conduit). This enclosure also includes 2 "J-Hooks" for ease of mounting. This exterior surface mounted enclosure is specifically designed to house communication / utility/security/home audio-video wiring demarcation devices.

This enclosure is also available with a splice chamber, please order: **BN30369WS-UL**

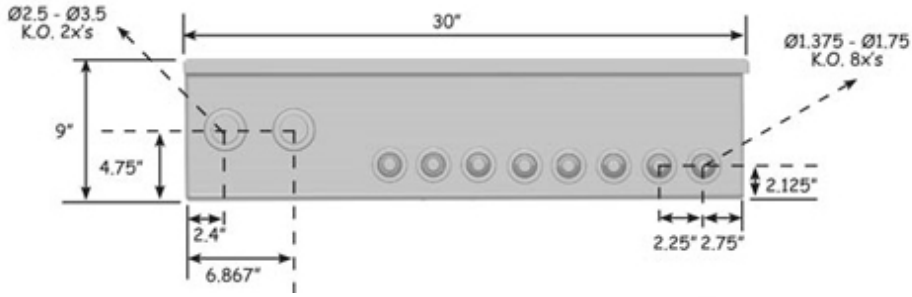

© 2006-2017 Benner Nawman, Inc. All Rights Reserved. Call us: [\(800\) 992-3833](tel:8009923833)  
3450 Sabin Brown Road • Wickenburg, AZ 85390 • [Sitemap](#)