



PUSH WIRE® connector for junction boxes; 6-conductor terminal block; transparent housing; violet cover

Item No.: 773-106



PUSH WIRE® connector for junction boxes; 6-conductor terminal block; transparent housing; violet cover

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	773-106
GTIN / EAN	4044918397681
Content	1
Order amount	50
Customer item number	

Notes

Safety information 2: When using conductors of exclusively the same cross section, 0.75 mm²/AWG 18 is also possible.

Technical data


Miscellaneous

Total number of connection points	6
Total number of potentials	1
Color	transparent
Pollution degree (1)	2

Technical data	
<i>Rated voltage (II / 2) [V]</i>	<i>400 [V]</i>
<i>Rated impulse voltage (II / 2) [kV]</i>	<i>4 [kV]</i>
<i>Rated current [A]</i>	<i>24 [A]</i>
<i>Pull-in time</i>	<i>0.0</i>
<i>Connection technology</i>	<i>PUSH WIRE®</i>
<i>Number of connection points connector</i>	<i>6</i>
<i>Actuation type</i>	<i>Push-in</i>
<i>Connectable conductor materials</i>	<i>Copper</i>
<i>Solid conductor</i>	<i>0.75 ... 2.5 mm² / 18 ... 12 AWG</i>
<i>Stranded conductor</i>	<i>1.5 ... 2.5 mm² / 16 ... 12 AWG</i>
<i>Strip length</i>	<i>12 mm / 0.47 Inch</i>
<i>Type of wiring</i>	<i>Side-entry wiring</i>
<i>Fire load [MJ]</i>	<i>0.075 [MJ]</i>
<i>Weight [g]</i>	<i>3.55 [g]</i>
<i>Width</i>	<i>18.8 mm / 0.74 Inch</i>
<i>Height</i>	<i>13.1 mm / 0.516 Inch</i>
<i>Depth</i>	<i>19.5 mm / 0.768 Inch</i>
<i>Safety information 1</i>	<i>In grounded power lines</i>

Images & drawings



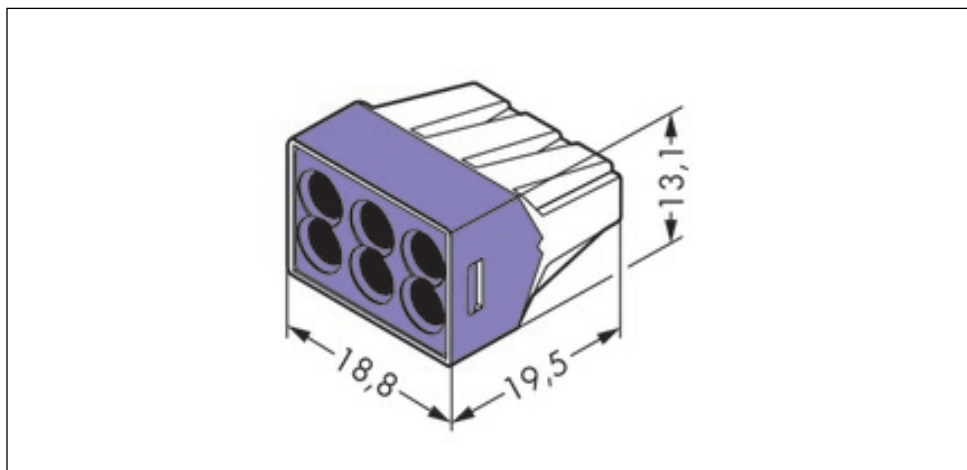

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.