



Classic filament LED Lamps

2A15/LED/822/FCL/ND 120V 6/1

Philips LED vintage-style lamps allow you to maintain a warm, classic light effect while providing longer life and energy savings.

Product data


General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	2-25W
Light Technical	
Color Code	822 [CCT of 2200K]
Initial lumen (Nom)	220 lm
Luminous Flux (Rated) (Nom)	220 lm
Color Designation	Warm/Extra Warm/Very Warm
Correlated Color Temperature (Nom)	2200 K
Luminous Efficacy (rated) (Nom)	110 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 or 60 Hz
Power (Rated) (Nom)	2 W
Lamp Current (Nom)	44 mA

Wattage Equivalent	25 W
Starting Time (Nom)	0.5 s
Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.4
Voltage (Nom)	110-130 V
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Clear
Approval and Application	
Energy Consumption kWh/1000 h	- kWh
Product Data	
Order product name	2A15/LEDFilament/822/CL/ND 120V
EAN/UPC - Product	046677461119
Order code	461111
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10

Classic filament LED Lamps

Material Nr. (12NC)	929001209604
Net Weight (Piece)	0.014 kg

Dimensional drawing

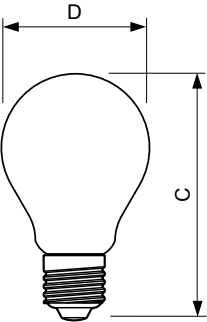

Filament Bulb A15 CL 2W-25W 250lm E26 ND

Product	D	C
2A15/LEDFilament/822/CL/ND 120V	47 mm	80 mm

Photometric data

