

SPECIFICATION SHEET

PRODUCT # : CL-648C-RC

•Area Lights

•Solid Copper

Fixture Specifications:

Housing: Corrosion resistant solid copper.

Stem: Solid copper pipe with 1/2" NPT on bottom.

Finish: RC- Raw Copper. Will age gradually over time.

Lens: Frosted polycarbonate, cover over lamp providing sprinkler water protection.

Socket: Top grade fixed ceramic bi-pin socket. Easy tool free lamp access.

Lamp: 12V, T3 halogen, 20W max. L-10T3 (10w) standard. LED lamps available in 2W and 2.5W. Xenon and halogen lamps also available. See lamp guide below for more information.

Wiring:

Fixture is prewired with a 18-2 SPT2-W direct burial cord. Wire connector available separately. Universal connector CX-839 or gel filled wire nut CX-854 may be ordered to Corona Lighting.

Mounting Spike:

Standard injection molded spike with 1/2" NPT threaded female hub.

Electrical Notes:


A remote 12V transformer required, may be ordered to Corona Lighting separately. Voltage range for 12V halogen lamps are 11V-12.5V. Voltage range for LED lamps are 10V-14V. Proper grease/lubricant is suggested on threaded parts during installation process.

Warranty:

Limited lifetime warranty on fixture housing and stem against manufacturer's defects.



2W and 2.5W

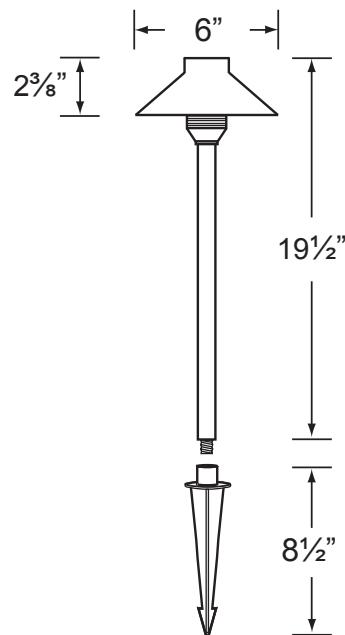

AVAILABLE LED LAMPS (Corona LED lamps have a five (5) year limited warranty against manufacturer's defects)

LAMP NUMBER	WATTS	BEAM		COLOR & TEMP.	RATED HOURS	HALOGEN EQUIVALENT
		SPREAD	LUMEN			
L-EDT3-2W	2	180°	150	2700K	25,000	20 Watt
L-EDT3-2.5W	2.5	180°	200	2700K	25,000	35 Watt
L-EDT3-2W-3K	2	180°	160	3000K	25,000	20 Watt
L-EDT3-2.5W-3K	2.5	180°	210	3000K	25,000	35 Watt

AVAILABLE HALOGEN LAMPS

LAMP NUMBER	WATTS	BEAM		COLOR & TEMP.	RATED HOURS
		SPREAD	LUMEN		
L-10T3	10		120	2950K	2,000
L-20T3	20		300	2950K	2,000
L-10T3/SC	10		120	2950K	2,000
L-10T3/SC	20		300	2950K	2,000

AVAILABLE XENON LAMPS

LAMP NUMBER	WATTS	BEAM		COLOR & TEMP.	RATED HOURS
		SPREAD	LUMEN		
L-X10T3	10		120	2950K	10,000
L-X20T3	20		350	2950K	10,000

JOB INFORMATION

TYPE:

DATE:

JOB NAME & ADDRESS:

PRODUCT #:

TOTAL QUANTITY:

LAMP TYPE & WATTAGE:

TRANSFORMER:

CONTRACTOR:

SPECIFIER:

• When ordering a halogen or xenon lamp add lamp number to the product number. If you are ordering LED lamps you should follow the format below:

• CL - product # - lamp - wattage

CL - 648C-RC - L-EDT3 - 2W-3K

Example: CL-648C-RC-L-EDT3-2W-3K

• Corona Lighting reserves the right to make any change and/or improvement to the design and construction of this fixture without further notification.