



# A-Shape LED

## 18A21/LED/827 3WAY ND 120V 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

### Product data


General Information	
Cap-Base	E26 [ Single Contact Medium Screw]
Nominal Lifetime (Nom)	25000 h
Switching Cycle	50000X
Technical Type	18-100W
Light Technical	
Color Code	827 [ CCT of 2700K]
Luminous Flux (Nom)	1600 lm
Luminous Flux (Rated) (Nom)	1600 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	88.88 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	18 W
Lamp Current (Nom)	170 mA
Wattage Equivalent	100 W
Starting Time (Nom)	0.5 s

Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	100 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	FR [ Frosted (FR)]
Approval and Application	
Energy star mark	Energy star
Suitable For Accent Lighting	No
Product Data	
Order product name	18A21/LED/827 3WAY ND 120V
EAN/UPC - Product	046677459161
Order code	459164
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6

A-Shape LED

Material Nr. (12NC)	929001174204
Net Weight (Piece)	0.155 kg

Dimensional drawing

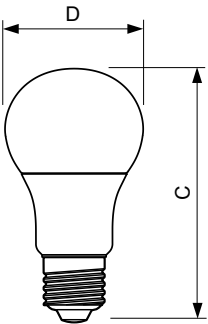

Bulb A21 120V 18-120W 1600lm 827 E26 ND

Product	D	C
18A21/LED/827 3WAY ND 120V	71.1 mm	134.6 mm

Photometric data

