



Color:  Ivory

UPC Code: 07847772353

Country Of Origin: China

NEMA:  
5-20R



## GFNL2-HGI

SmartlockPro GFCI Duplex Receptacle Outlet, Heavy-Duty Hospital Grade, Tamper-Resistant, Power Indication, 20 Amp, 125 Volt, Back or Side Wire, NEMA 5-20R, 2-Pole, 3-Wire, Self-Grounding - Ivory

Peace of mind, all the time. The SmartlockPro Self-Test GFCI tests itself even if you forget. Designed to meet the latest UL standard for auto-monitoring (self-test) our complete line of self-test GFCIs periodically conduct an automatic internal test to confirm that it can respond to a ground fault. With the slimmest profile on the market, the device allows for fast and easy installation, while Leviton's patented reset lockout mechanism prevents reset of the GFCI if it is not wired or operating correctly. The SmartlockPro Self-Test GFCI is the smart choice in ground fault circuit interrupter protection.

### Technical Information

AC Horsepower Ratings

**At Rated Voltage:** 1 HP

**Brand:** SmartlockPro

Electrical Specifications

**Amperage:** 20 A

**Grounding:** Self-Grounding

**Pole:** 2

**Short Circuit Current Rating:** 10kA

**Voltage:** 125 VAC

**Wire:** 3

Environmental Specifications

**Flammability:** Rated V-0 per UL 94

**Operating Temperature:** -35C to +66C

Material Specifications

**Body Material:** Polycarbonate

**Face Material:** PBT

**Ground Clips:** Brass

**Grounding Screw:** Plated Steel

**Line Contacts:** Brass

**Shutter Mechanism:** Delrin® Acetal

**Strap Material:** Galvanized Steel

**Terminal Clamp:** Brass

**Terminal Screws:** Plated Steel

Mechanical Specifications

**Product ID:** Ratings are permanently marked on device

**Terminal Accom.:** 14-10 AWG solid or stranded

**Terminal ID:** Brass-Hot, Green-Ground, Silver-Neutral

**Termination:** Back or Side Wire

Product Features

**Amperage:** 20 A

**Brand:** SmartlockPro

**Color:** Ivory

**Device Type:** Duplex Receptacle Outlet

**Function:** GFCI

**Grade:** Heavy-Duty Hospital Grade

**NEMA:** 5-20R

Standards and Certifications

**ANSI:** C-73

**Applicable Standards:** UL 943, UL 498, CSA C22.2 No. 42 & 144, FedSpec W-C-596

**Certification/Listing:** UL, CSA, NOM-ANCE

**NEMA:** WD-1 & WD-6


Warranty

**Product Warranty:** 2-Year Limited

Patents\*

CA2341552	US6864766
CA2358721	US6944001
CA2425810	US7336458
CA2427366	US7355117
CA2515035	US7400479
CA2621644	US7463124
CA2677283	US7697252
MX234458	US7737809
MX251584	US7764151
MX269232	US7820909
MX276411	US7862350
MX276626	US7868719
MX302458	US7907371
MX308495	US8004804
MX315596	US8054595
US6040967	US8130480
US6246558	US8242362
US6282070	US8444309
US6381112	US8547126
US6437953	US8587914
US6646838	US8599522
US6657834	US9053886
US6788173	USD674753

\*This list is provided for patent marking purposes only. A good faith effort is made to maintain the accuracy and completeness of this list. No legal inference should be drawn from the omission of a patent from this list.

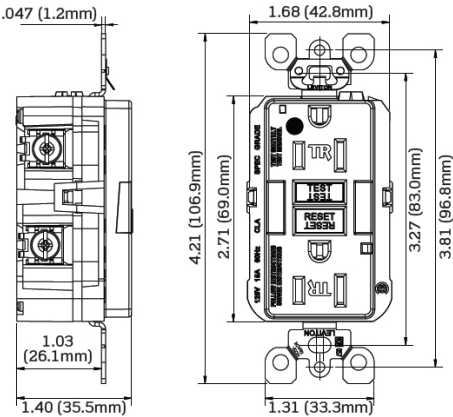

SPECIFICATION SUBMITTAL

JOB NAME: <input type="text"/>	CATALOG NUMBERS: <input type="text"/>	
	JOB NUMBER: <input type="text"/>	<input type="text"/>

**Leviton Manufacturing Co., Inc.**

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):  
+1-800-824-3005

**Leviton Manufacturing of Canada, Ltd.**

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

**Leviton S. de R.L. de C.V.**

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-  
1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

**Visit our Website at: [www.leviton.com](http://www.leviton.com)**

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

**Leviton has a global presence.**

If you would like to know where your local Leviton office is located please go to:

[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

