

GH48R Electric Fan-Forced Garage Heater



Remote control requires 2 each
AAA batteries - Not Included



Intertek
Conforms to ANSI/UL 2021
and CSA C22.2, No. 46 Safety
Standards




- ▶ **CONTROL YOUR COMFORT**
 - BUILT-IN DIGITAL INTERFACE
 - REMOTE CONTROLLED
 - 9 HOUR TIMER
 - WITH AUTO SHUT-OFF
- ▶ **PERFECT FOR 2 CAR GARAGE**
 - 4800 WATTS AND 16,378 BTU'S/HR
- ▶ **RESIDENTIAL GRADE UNIT HEATER**
 - DURABLE UNIT WITH SCRATCH AND RUST RESISTANT FINISH
- ▶ **APPLICATIONS INCLUDE:**
 - GARAGES
 - SMALL WAREHOUSES
 - STORAGE FACILITIES
 - WORKSHOPS
 - *AND MUCH MORE*



GH48R Electric Fan-Forced Garage Heater

SELECTION CHART

| CATALOG NUMBER | UPC | VOLTS | WATTS | AMPS | BTU/HR | SHIP L" x W" x H" | SHIP WEIGHT |
|----------------|----------------|-------|-------------|------------|--------------|-------------------|-------------|
| GH48R | 00685360165691 | 240 | 4800 / 2400 | 20 / 10 | 16378 / 8189 | 17-3/4 x 12 x 18 | 13 lbs |
| | | 208 | 3600 / 1800 | 17.3 / 8.6 | 12284 / 6142 | | |

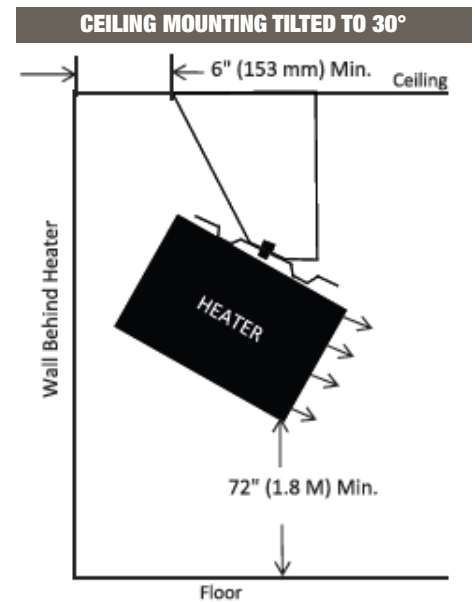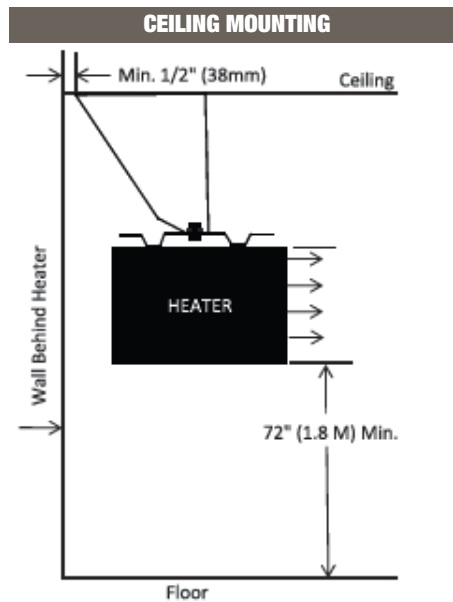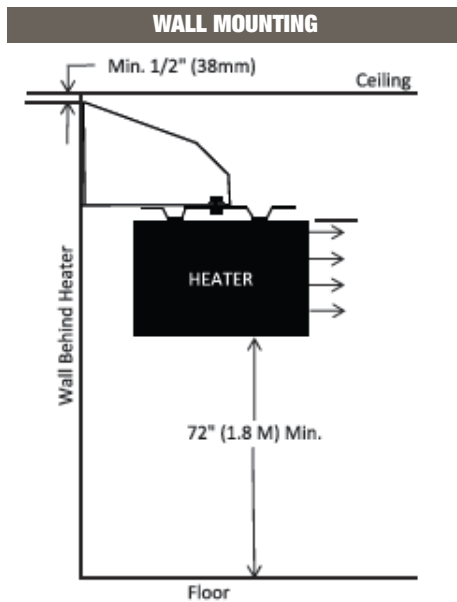

FEATURES

- ▶ 240V – 4800 watt / 208V – 3600 watt Garage / Utility Heater
- ▶ Hardwired to provide easy installation and clean aesthetic look
- ▶ Remote Control included for easy operations (batteries not included)
- ▶ Digital LED Interface
- ▶ Optional timer feature up to nine hours with automatic shut off
- ▶ Thermostat ranges from 45° F – 99° F
- ▶ Built-In Fan Delay to prolong element life
- ▶ Power Indicator Light
- ▶ Stainless Steel tubular heating element
- ▶ Includes mounting bracket for wall or ceiling installation
- ▶ 1 year warranty

