

- Steel Products
- NEMA Enclosures
- Weatherproof Products
- Electrical Fittings
- Wiring Devices
- Exit & Emergency Lighting
- Landscape Lighting
- Line Voltage/HID Lighting
- LED Lighting
- Ventilation Fans
- Cable & Wire
- Industry Cross Reference

Newsletter


Sign Up for Our Newsletter:

* Name

* Email

* Company

Subscribe

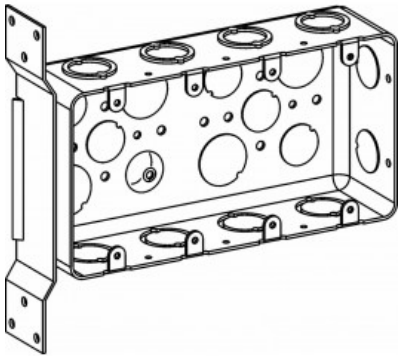

MORE VIEWS



DHB-4-FB

Be the first to review this product

2-1/8" DEEP, 4-GANG DRAWN MULTIGANG HANDY BOX WITH FB BRACKET

Download Spec Sheet

- Email to a Friend
- Print
- Tweet
- G+

- Product Description
- Product Tags

Category	SWITCH BOX
Page	A22
Barcode	8-35243-00107-7
Features:	
	- Raised Ground Emboss & Device Ears
	- FB Bracket for offset mounting on flat side of stud or joist
Dimensions:	
Width	7-1/2"
Height	4"
Depth	2 - 1/8"
Cu In	57.8
Line Drawings	
Specifications:	
Material	16 GA Sheet Steel
Mfg. Process	Drawn
Bracket	FB, 9/16"
No. of Gangs	4
KO Sides	(2) - 1/2", (8) - CKO
KO Bottom	(5) - 1/2", (4) - 3/4"
Packaging Info:	
Std Pkg	20
Weight	32 lbs
Certifications:	
UL File Number:	E227970