



U217MTBPL
100A 7T RT OU MAIN
784572178878

Brand Name: Milbank

Type: Ring Type Meter Socket

Application: Meter Socket With Main And Load Center

Standard: UL Listed

Voltage Rating: Up to 240 Volts Alternating Current

Amperage Rating: 100 Continuous Ampere

Phase: 3 Phase

Frequency Rating: 60 Hertz

Size: 4.625H x 25W x 24.75H

Number Of Cutouts: 1

Cutout Size: 100 Ampere Main Fuse Pull Out Switch

Cable Entry: Overhead and Underground

Terminal: Single Mechanical Line Side and Single Mechanical Load Side Connector

Insulation: Fiberglass with Resin

Mounting: Surface Mount

Enclosure: Type 3R, G90 Galvanized Steel with Powder Coat Finish

Jaw Quantity: 7 Terminal

Bypass Type: Link Bypass


Number of Metered Positions: 1 Position

Equipment Ground: Ground Lug

Hub Opening: Twin Small Closing Plates

Line Side Wire Range: 14 AWG - 1/0

Number Receptacles: 0

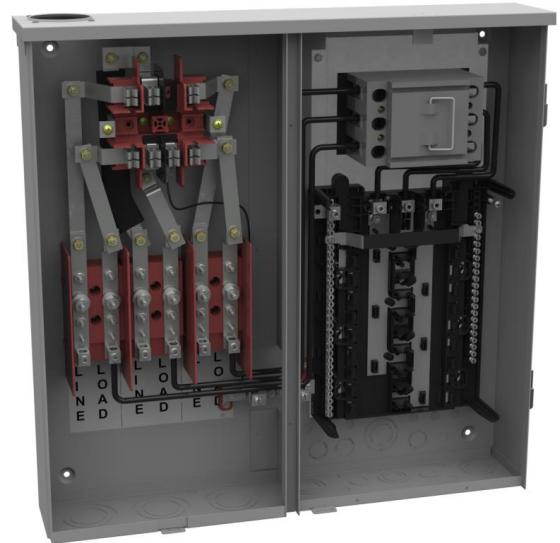

Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.