




ILSCOM® TWCT COPPER C-TAP THIN WALL

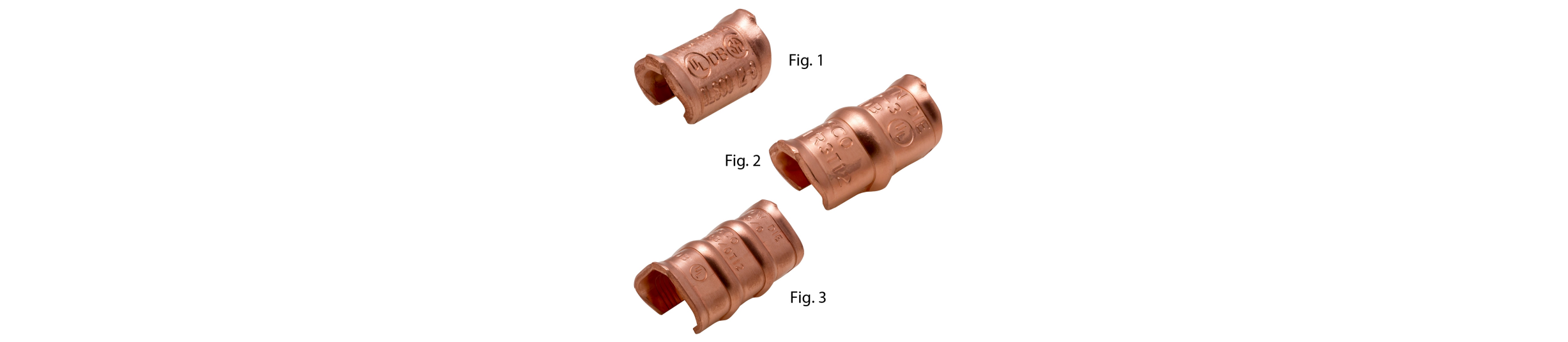

- Manufactured from high conductivity copper for maximum conductivity and low resistance
- Stamped with wire size, die index and part number for clear and easy identification
- Range taking reduces inventory
- UL and CUL listed for grounding, bonding and power
- When used for power application, and if proper high voltage spacing and insulation techniques are used, may be used for high voltage applications up to 35KV
- Direct burial in earth or concrete
- Bright dip finish, resist corrosion and oxidation
- Tested to UL 486A/B, UL file E6207
- Tested to UL 467, UL File E6207

Item ID	Figure Number	Conductor Range Main	Conductor Range Tap	Length	Color Code	Die Index Number	Strip Length	Standard Package Quantity	NAED/UPC Number
TWCTR6T12	1	6-8 AWG	8-12 AWG	0.6200	GRAY	8	0.6825	25	0783669689396