

Rigid Conduit Bodies

Threaded TB Type - Malleable Iron

Features

- NPT tapered hubs

Applications

- Provides access to conductors for pulling, splicing and maintenance

Standard Material


- Malleable iron

Standard Finish

- Zinc plated, aluminum enameled



UL Standard: 514A
Fed. Spec. W-C-586D
NEMA FB 1

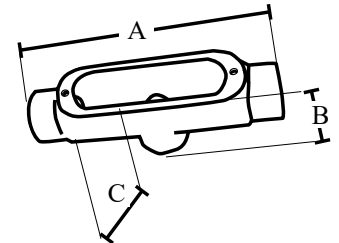

Catalog Number	UPC	Size	Wire Size		Internal Volume (in ³)	Ship Case	Weight/ Case	Inches		
			Max. Number	Max. Size				A	B	C
TB1M	17545	1/2"	---	---	5.6	10	10	5.25	1.9375	1.9375
TB2M	17546	3/4"	3	6 AWG	9.5	10	6	6.0625	1.5625	1.5625
TB3M	17547	1"	3	4 AWG	15	5	20	7.125	1.8125	1.8125
TB4M	17548	1-1/4"	3	2 AWG	33	5	19	9.3125	2.4375	3.75
TB5M	17549	1-1/2"	3	1 AWG	36	2	20	9.3125	2.4375	3.75
TB6M	17550	2"	3	2/0 AWG	75	1	13	11.8125	3.8125	4.125