


E12LED102

CRI 80 2700K 300 Lumens LED Filament

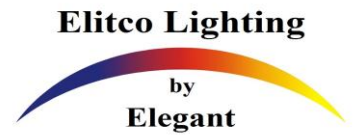

Project

Location

PRODUCT DESCRIPTION

producing over 300 lumens, 4.5W ; LED Filament is designed to provide 15,000 hours of life.

SPECIFICATIONS:

- a.Lamp power: 4.5W
- b.Power factor ≥ 0.8 ;
- c. 2700K LED color temperature ;
- d. 80 CRI minimum; Accommodates 120 volts AC at 60Hz ;
- e. Dimmable with most standard incandescent as dimming list which provided.


INSTALLATION:

connect to city power directly

DIAMETER: 35mm /1.38inch

FINISHES: Clear Cover

LABELS: UL/CUL listed (CUL listed number: E352204) , FCC Listed,
Suitable for damp locations

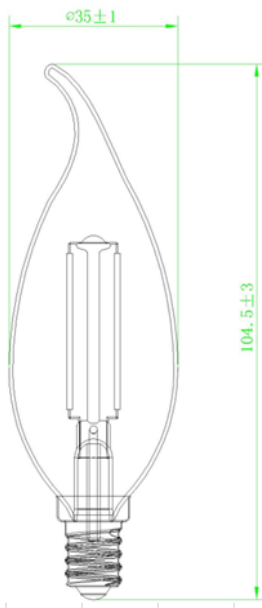

COMPATIBLE HOUSINGS

Model

Description

E12LED102	LED filament
-----------	--------------