


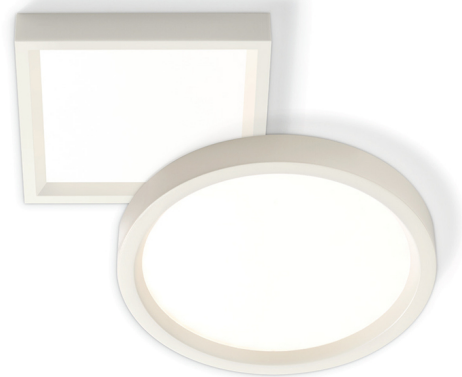

SlimSurface LED Downlight

SlimSurface LED downlight, 5-inch round, surface mount, 80 CRI, 3000K CCT, 650 lm, 120V, Standard (TRIAC) dimming, wet location, Black finish

SlimSurface LED downlight, 5-inch round, surface mount, 80 CRI, 3000K CCT, 650 lm, 120V, Standard (TRIAC) dimming, wet location, Black finish

SlimSurface LED is a low profile downlight intended for ceiling or wall mount applications. This 0.625" thick luminaire offers the appearance of a recessed downlight but is actually surface mounted.

Product data

General Information		Shape	
Lamp Source Code	LED	Round	
Color Temperature	3000K		
CRI	80	Initial Performance (IEC Compliant)	
Downlight Type	Open Downlight	Luminaire Lumens	
Photometric Distribution Type	Direct	650	
Mounting	Surface Wall		
Operating and Electrical		Product Data	
Luminaire Input Watts	10	Order product name	SlimSurface LED downlight, 5-inch round, surface mount, 80 CRI, 3000K CCT , 650 lm, 120V, Standard (TRIAC) dimming, wet location, Black finish
Voltages	120 V	Commercial Code	S5R830K7BK
Mechanical and Housing		Order code	S5R830K7BK
Aperture Size Code	5 in	Catalog Number Description	SlimSurface LED downlight, 5-inch round, surface mount, 80 CRI, 3000K CCT , 650 lm, 120V, Standard (TRIAC) dimming, wet location, Black finish

SlimSurface LED Downlight

Service / Spec Smart	-
Material Nr. (12NC)	LIGU60013821

