


A21LED203-6PK

CRI 80 2700K 500/1100/1600 Lumens Dimmable LED bulb

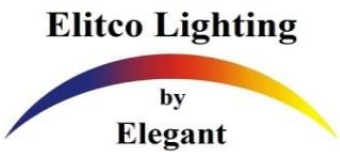

The high performance LED A21 architectural form and versatility to make it an excellent choice for new construction or retrofit applications.

Performance

- LED A21 is designed to provide 25000 hours of life
- Energy-saving & Super bright, saving 75% energy compared
- ETL and FCC compliant, for use indoor only.

Construction

- IP20 Waterproof

Installation

- To ensure safety, please disconnect power before installation and changing Bulb.
- Size: $\Phi 2.76$ " (70mm) * H5.28" (134mm)



Specifications

Category	Light Bulb	Inner Package Length (Inch)	5.6
Bulb Shape	A21-3Way	Inner Package Width (Inch)	8.5
Bulb Base Type	E26	Inner Package Height (Inch)	5.9
Bulb Base Finish	Chrome	Inner Package Weight Per Unit (Lbs)	3.5
Color Temperature	2700K	Inner Package Quantity	6
Beam Angle	OMNI300°		
Finish	White		
CRI	80		
Average Life (Hours)	25000		
Estimated Yearly Energy Cost (11 ¢ /Kwh)	2.05		
Life Based On 3Hrs/Day (Years)	22.83	Lamp Type	LED
Product Length (Inch)	N/A	Dry/Wet/Damp	Dry
Product Width (Inch)	2.76	Energy Star	Yes
Product Height (Inch)	5.28	Power Factor	0.9
Product Extension (Inch)	N/A	Current	40/75/100mA
Product Weight Per Unit (Lbs)	0.35	Lumen/Watt	94.12/100/100
Dimmable	Yes	Warranty (Year)	2
Watts	5/11/17W	DLC (Yes/No)	No
Watt Equivalent	40/75/100W	Input Voltage	120V;60Hz
Lumens	500/1100/ 1600	Housing Material	Aluminum alloy+High thermal conductive plastic
Certification (UL/ETL/FCC)	ETL	Lens	Frost
Individual Box Length (Inch)	5.67	Led Type	Luminus
Individual Box Width (Inch)	2.79		
Individual Box Height (Inch)	2.79		
Individual Box Wight Per Unit (Inch)	0.41		