

CAT5E 48 PORT PATCH PANEL

19" RACK MOUNTABLE



DESCRIPTION

CAT5E 48 Port Panel, 110 Type Termination.
19" Rack Mountable.

FEATURES

- High Impact Patch Panel
- Tough Black Painted Finish
- Number Labeled for Easy Identification
- 568A & 568B Wiring Color Codes
- 110 Type Termination
- ISO/IEC 11801, ANSI/TIA/EIA 568C.2

SKU: 041-373/48

Panel Housing

Material	SPCC
Thickness	1.5mm
Plated	Black
Dimension	EIA-310D (2U)

IDC Connector

IDC Connector	110 Type
IDC Housing	PC+Glass Fiber, UL 94V-2
IDC Terminal	Phosphor Bronze, Tin Plated
Compability	22-26AWG Solid Wire

Jack Connector


Contact Material	Phosphor Bronze w/ Nickel Plated
Contact Finish	50μ Gold Plated (Plug contact area)
Jack Housing	ABS, UL 94V-0

Printed Circuit Board

Material	FR4, UL 94V-0
----------	---------------

Operating Temp. -10° to 60° C

Accessories: Cable Ties

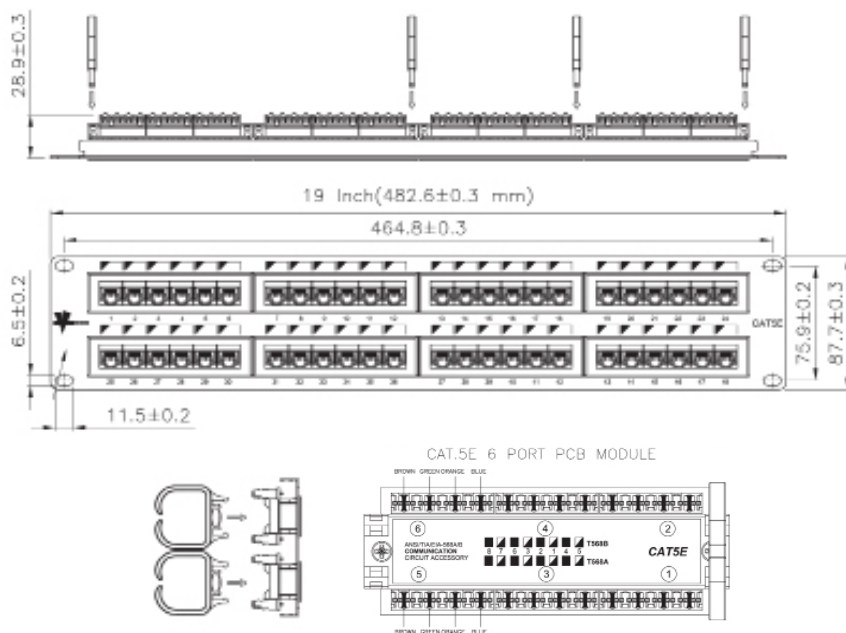

VERTICAL CABLE

951.696.7772 California

800.749.2447 Florida

845.391.8318 New York



www.verticalcable.com

Rev. 01/2014

Subject to change without notice.