


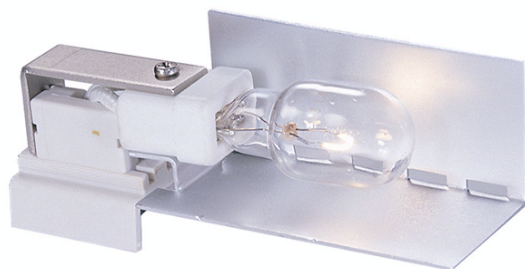

9433-15: Lx Wedge Base High Wattage Lampholder



Dimensions:

Length:	3"
Width:	15/16"
Height:	1 1/4"

Bulbs:

- 1 - Xenon Wedge T5 18w Max. 12v - Not included
- 1 - Xenon Wedge T5 8w Max. 12v - Not included
- 1 - Xenon Wedge T5 18w Max. 24v - Not included
- 1 - Wedge T5 8w Max. 12v - Not included
- 1 - Wedge T5 12w Max. 12v - Not included
- 1 - Wedge T5 18w Max. 12v - Not included

Material List:

- 1 Holder - Polycarbonate - White
- 1 Reflector - Anodized Aluminum -

Safety Listing:

- UL Listed for Damp Locations
- cUL Listed for Damp Locations
- cETL Listed for Damp Locations

Instruction Sheets:

English (HC-257)

Collection: Lx Wedge Base Lampholders

For use with our xenon and incandescent wedge base lamps, Ambiance Lx Wedge Base Lampholders feature a high quality reflector for minimizing light loss from your selected lamps. Each lampholder snaps onto Lx Track and Cable with ease and minimum spacing of 6 inches on center. Recommended where maximum illumination is required - high cove applications, commercial displays or high level task lighting. Replacement lamps: 9774, 9775, 9776, 9777, 9778

Breakaway anodized aluminum reflector with white finish. Heat resistant polycarbonate. Ceramic socket.

Listed for wet locations, 12v only, and damp locations, 24v only. Snap directly onto 9435 track and easily cut track to desired length.

NOTE - Wet location for 12V only

UPC #:785652943355

Finish: White (15)

Replacement Bulb Data:

Product #			Type	Base	Watts	Watts Consumed	Volts	Hours	Lumens	Temp (°K)	CRI
9774	Clear Glass Lens	Xenon	T5	Wedge	18	16.2	12v	10000	210	2800	90
9776	Clear Glass Lens		T5	Wedge	8	8	12v	2500	57	2650	90
9775	Clear Glass Lens	Xenon	T5	Wedge	18	16.2	24v	10000	210	2800	90

9776	Clear Glass Lens		T5	Wedge	8	8	12v	2500	57	2650	90
9777	Clear Glass Lens		T5	Wedge	12	11.6	12v	2000	120	2750	90
9778	Clear Glass Lens		T5	Wedge	18	16.2	12v	2000	210	2800	90

Shipping Information:

Package Type	Product #	Quantity	UPC	Length	Width	Height	Cube	Weight	Frt. Class	UPS Ship
Individual	9433-15	1	785652943355	5.38	2.75	1	0.009	0.047	100	Yes
Master Pack		20	10785652943352	10	9	2.5	0.13	0.95	100	Yes
Shipping Master		500	20785652943359	17.25	17.25	15.25	2.626	23.5	100	Yes
NJ Pallet		9000		48	40	49.5	55	472		No
NV Pallet		9000		48	40	49.5	55	472		No