

SURGE SUPPRESSOR, RC COUPLING, AC
127...240V, DC 150...250V, FOR MOTOR
CONTACTORS SZ S0,



General technical data:		
product brandname		SIRIUS
Product designation		surge suppressor
Size of contactor		S0
Design of the surge suppressor		with RC elements
Ambient temperature		
• during storage	°C	-40 ... +80
• during operation	°C	-25 ... +60
Control circuit/ Control:		
Type of voltage of the control supply voltage		AC/DC
Control supply voltage frequency		
• 1 rated value	Hz	50
• 2 rated value	Hz	60
Control supply voltage 1		
• at DC		
— Initial rated value	V	150
— Final rated value	V	250
• at AC		

- at 50 Hz Initial rated value
- at 50 Hz Final rated value
- at 60 Hz Final rated value
- at 60 Hz Initial rated value

V	127
V	240
V	240
V	127

Installation/ mounting/ dimensions:

Mounting position		any
Mounting type		clip-on
Width	mm	30
Height	mm	19
Depth	mm	12

Certificates/ approvals:

Certificate of suitability CE / UL / CSA / CCC

General Product Approval

Declaration of Conformity

Test Certificates

Shipping Approval



CSA



UR



EG-Konf.

[Special Test Certificate](#)



ABS

Shipping Approval



GL



LRS



PRS



RINA



RMRS

other

[Confirmation](#)



VDE

Railway

[Vibration and Shock](#)

Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrymall>

Cax online generator



<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RT2926-1CD00>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RT2926-1CD00>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

 http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RT2926-1CD00&lang=en

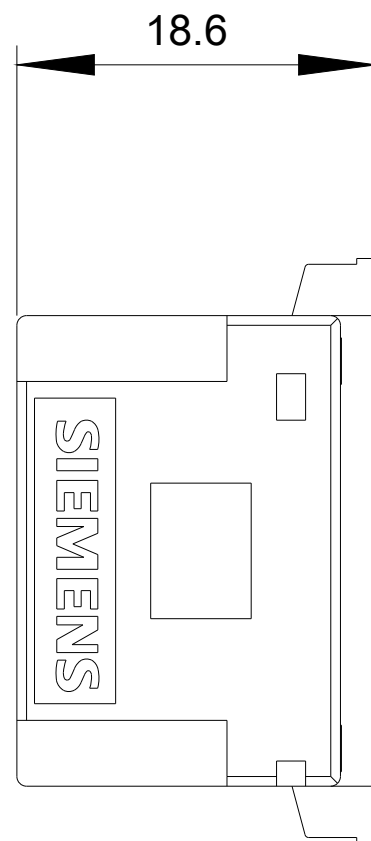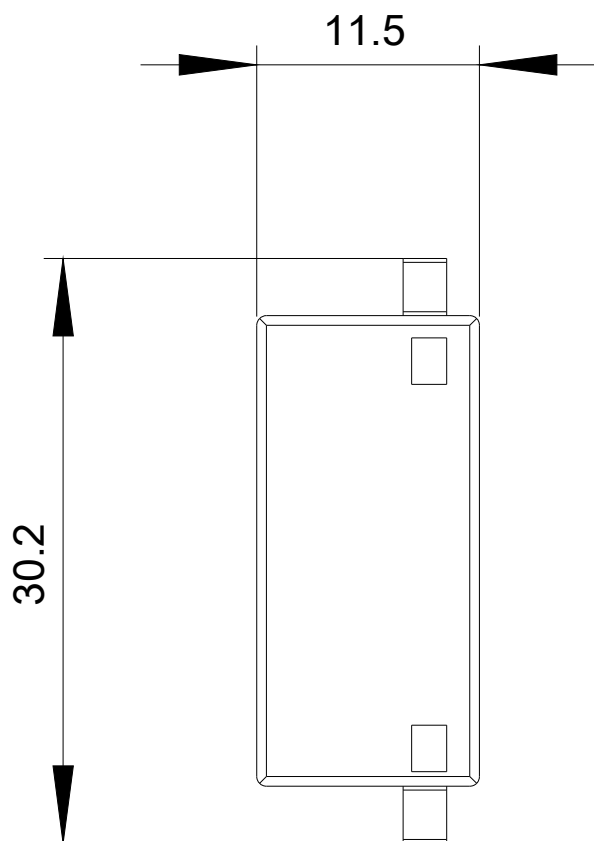



last modified:

07/19/2017