

Classic filament LED Lamps

4.5BA11/LEDFilament/820/CL-A/DIM 120V

Philips LED vintage-style lamps allow you to maintain a warm, classic light effect while providing longer life and energy savings.

Product data

General Information	
Cap-Base	E12 [Candelabra Screw]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	4.5-40W
Light Technical	
Color Code	820 [CCT of 2000K]
Initial lumen (Nom)	350 lm
Luminous Flux (Rated) (Nom)	350 lm
Color Designation	Flame
Correlated Color Temperature (Nom)	2000 K
Luminous Efficacy (rated) (Nom)	77.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Rated) (Nom)	4.5 W
Lamp Current (Nom)	50 mA


Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	100 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Clear (CL)
Approval and Application	
Energy Saving Product	Yes
Suitable For Accent Lighting	No
Product Data	
Order product name	4.5BA11/LEDFilament/820/CL-A/DIM 120V

Classic filament LED Lamps

EAN/UPC - Product	046677466527
Order code	466524
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6

Material Nr. (12NC)	929001268704
Net Weight (Piece)	0.024 kg

Dimensional drawing

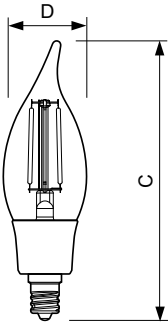

4.5BA11/LEDFilament/820/CL-A/DIM 120V

Product	D	C
4.5BA11/LEDFilament/820/CL-A/DIM 120V	35 mm	115 mm

Photometric data

