



# A-Shape LED

9.5A19/LED/850 ND 120V 6/1

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

## Product data

### General Information

Cap-Base	E26 [ Single Contact Medium Screw]
Nominal Lifetime (Nom)	10950 h
Switching Cycle	50000X
Technical Type	9.5-75W

### Light Technical

Color Code	850 [ CCT of 5000K]
Initial lumen (Nom)	1000 lm
Luminous Flux (Rated) (Nom)	1000 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	105.26 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

### Operating and Electrical

Input Frequency	60 Hz
Power (Rated) (Nom)	9.5 W
Lamp Current (Nom)	160 mA
Wattage Equivalent	75 W
Starting Time (Nom)	0.5 s

Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	120 V

### Temperature

T-Case Maximum (Nom)	100 °C
----------------------	--------

### Controls and Dimming

Dimmable	No
----------	----

### Mechanical and Housing

Bulb Finish	Frosted (FR)
-------------	--------------

### Approval and Application

Suitable For Accent Lighting	No
------------------------------	----


### Product Data

Order product name	9.5A19/LED/850 ND 120V
EAN/UPC - Product	046677463014
Order code	463018
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001219424

A-Shape LED

Net Weight (Piece)	0.052 kg
--------------------	----------

Dimensional drawing

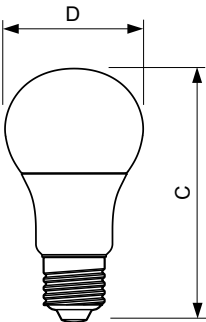

Bulb A19 120V 9.5W-75W 100D 5000K E26 ND

Product	D	C
9.5A19/LED/850 ND 120V	61 mm	107 mm

Photometric data

