



TYPE \_\_\_\_\_

CATALOG# \_\_\_\_\_

## EANY

### 8 Inch Extruded Aluminum LED Exit Sign New York City Approved

#### GENERAL DESCRIPTION

The Metro series LED exit provides high quality extruded aluminum construction, at low operating costs. Illumination is provided utilizing the highest quality LEDs (AlInGaP) for precise evenly distributed trouble free operation.

#### HOUSING

Specification grade rugged, durable Extruded aluminum construction offers superb corrosion resistance with polyester powder coat finish available in white or black standard.

#### MOUNTING

Universal quick and easy installation. All units are shipped with parts necessary to make sign either top, end, back mount version with Two Stencils. Housing top and ends have knockouts to accommodate ceiling and end mounting. Pendant mounting kit available (See options below).

#### FACE DESIGN

Provides 8" letters with 1" stroke. Stencils have easy to use directional marking knockouts.

#### ILLUMINATION

Red models provide High Output AlInGaP LEDs per face with rated lamp life of 10 years. Unit draws 3 Watts.

#### ELECTRONICS

Input is dual volt standard 120/277 60Hz. Unit is damp location listed 50°-104°F (10°-40° C). EM option features solid state design with low voltage disconnect, AC lockout, brown out protection, and AC indicator LED with test switch. Battery is maintenance free Nickel Cadmium.

#### CODE COMPLIANCE

Tested and Listed to UL 924 for damp location, meets or exceeds NFPA, NEC, and OSHA illumination standard. NYC approved.



#### WARRANTY

5 years on housing and electronics with a 7 year pro rated warranty on battery.




NY Calendar Number  
45619

#### DIMENSIONS

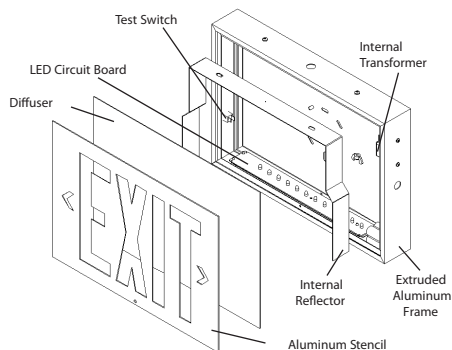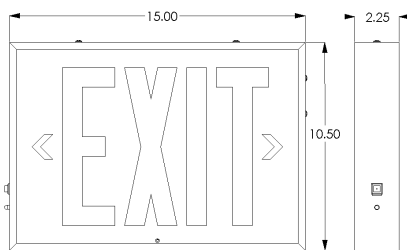

INDUSTRIAL SERIES

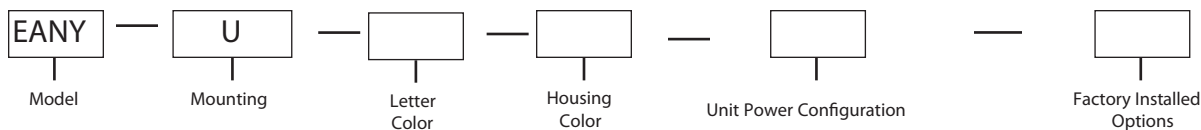

U=Universal Mounting  
Includes Canopy, 2 Stencils,  
2 Diffusers and 1 Back

R=Red  
G=Green

W=White  
B=Black

AC  
EM

AC Only  
Emergency Battery

DI=Two Transformer Input  
FL=Flasher Only (Battery Units Only)  
Flashes When Unit Goes Into Emergency Condition  
FA=Fire Alarm Panel Interface (AC and Battery Units)  
Flashes in Both Modes When Signal From Fire Alarm Panel is  
Received (6 to 24 VDC)  
FLA=FL Option W / Audible Alarm (Battery Units Only)  
FAA=FA Option W / Audible Alarm (AC and Battery Units)

