



High Efficacy
design



110 lm
per watt

50,000
Rated
Life Hours

LED Utility Wrap

29W

naturalLED® now offers the perfect solution for your lighting needs with the LED utility fixture. These fixtures are designed for saving energy and easy installation. Available in 29 watt and delivers up to 3,220 lumens, excellent, consistent color.

Our Utility Wrap features a full wrap around acrylic prismatic lens and is 4' long designed for end to end installation and works great in parking garages, stairwells, offices, hallways industrial, commercial and residential, ceiling or wall mounted. This fixture is versatile and efficient.

Key Features & Benefits

- ▶ Easy installation
- ▶ Uniform and consistent color
- ▶ Excellent thermal design
- ▶ Low power consumption
- ▶ Ceiling or wall mounted
- ▶ Universal Voltage 120-277V
- ▶ UL Damp Rated - for covered use only

Applications

- ▶ Conference/Meeting Rooms
- ▶ Stairwells
- ▶ Schools/Universities
- ▶ Hospitals
- ▶ Hotels
- ▶ Parking Garages

Color Choices



White
w/ white lens

Qualifications



ORDERING INFORMATION


2

Item Code	Description	Color Temp	Wattage	Lumen Output	Equivalent Wattage	Size	Rated Hours	UL Damp	DLC
7074	LED-FXUWS29/40K	4000K	29	3,220	2-3 & 4 FT8	7"x48"	50,000	•	•

DETAIL SPECIFICATIONS

► Dimensions

Wattage	A	B	C	Weight (lbs)
29W	48-in	7.00-in	2.4-in	3.85-lbs

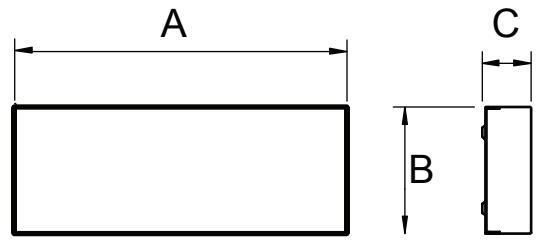

PACKAGE

► Master Carton Package

