


# I CAN'T BELIEVE IT'S NOT RECESSED

LED Functional Ceiling Light

FM-616

# WAC LIGHTING

Responsible Lighting®

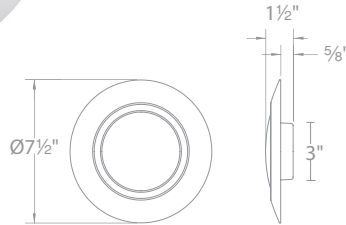

Fixture Type:

Catalog Number:

Project: \_\_\_\_\_

Location: \_\_\_\_\_

## PRODUCT DESCRIPTION

Multiple mid-powered LEDs illuminate the opaque diffuser uniformly without socket shadows which are common in conventional flush mounts.

## FEATURES

- Energy Star® rated
- Damp Location Listed
- CEC Title 24 Compliant
- UL & cUL listed
- ADA compliant
- Imitates a traditional 6" Line voltage recessed downlight with an R30 light bulb
- Uses 4" octagonal junction box or junction box with minimum dimensions of 4"x4"x1.5" (*not a combination 3/0-4/0*)
- Multiple LED array for uniform illumination
- 120VAC - no driver needed
- 54,000 hour rated life
- 5 year warranty

## SPECIFICATIONS

 
**Construction:** Aluminum with translucent diffuser

**Input:** 120VAC

**ELV Dimming:** 100% - 10% Electronic Low Voltage, 100%-5% Triac

**Operating Temperature:** -20°C (-4°F) to 40°C (104°F)

## ORDERING NUMBER

	Watt	Mounting	Color Temp	CRI	LED Lumens	Delivered Lumens	Finish
<b>FM-616</b>	16W	Install over a 4" junction box only	<b>930</b> 3000K	90	1150	1050	<b>WT</b> White 

## FM-616-930-WT

wacighting.com  
Phone (800) 526.2588  
Fax (800) 526.2585

Headquarters/Eastern Distribution Center  
44 Harbor Park Drive  
Port Washington, NY 11050

Central Distribution Center  
1600 Distribution Ct  
Lithia Springs, GA 30122

Western Distribution Center  
1750 Archibald Avenue  
Ontario, CA 91760