



Compact, tough and good looking cast aluminum housing with hinged framed glass lens. Integra Hood glare shield and stainless steel clip. Lamp supplied.

Color: Bronze

Weight: 7.5 lbs

Project:

Type:

Prepared By:

Date:

Lamp Info

Type: ED17
Watts: 50W
Shape/Size: N/A
Base: N/A
ANSI: N/A
Hours: 10,000
Lamp Lumens: 3,400
Efficacy: 47 LPW

Ballast Info

Type: BMHN50
120V: 2/1.6A
208V: N/A
240V: N/A
277V: N/A
Input Watts: 72W
Efficiency: 69%

Technical Specifications

Listings

UL Listing:

Suitable for wet locations. Suitable for ground mounting.

EISA 2007 Compliant:

This product complies with the new law for metal halide ballast efficiency. This law goes into effect January 1st, 2008. Pulse Start offers Longer Lamp Life, Faster Start-up and Faster Restrike.

Electrical

Sockets:

Porcelain with all copper current carrying components

Socket:

Glazed porcelain 4kv pulse rated with nickel plated screw shell and spring contacts

Construction

Housing:

Precision die cast aluminum, 1/2" NPS threaded arm with locking swivel fits all standard mounting boxes

Reflector:

Anodized semi-specular aluminum

Lens:

Thermal tempered shock resistant glass

Lens Gasket:

High temperature tubular silicone set in die cast retaining groove remains in place during relamping

Finish:

Formulated for high-durability and long lasting color

EPA:

0.43.

Other


Patents:

Pat. D420,458.

Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

Dimensions

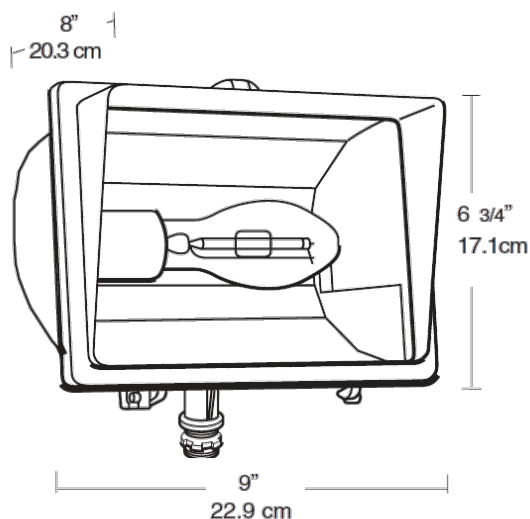

Features

Easy clip for tool-less relamping with Vandal proof screw capability

Integra hood glare shield for friendly lighting when properly aimed

Silicone gasket stays in place for durable weatherproofing & easy relamping

Precision die cast aluminum housing with durable polyester powder coating

Variable beam spread with 2 position adjustable socket

Long life lamp included

Mounting arm with sturdy locking teeth & internal gasket