


# Aluminum Bullyte (1020) Specification Sheet

Project Name:	Location:	MFG: Philips Hadco
Fixture Type:	Catalog No.:	Qty:

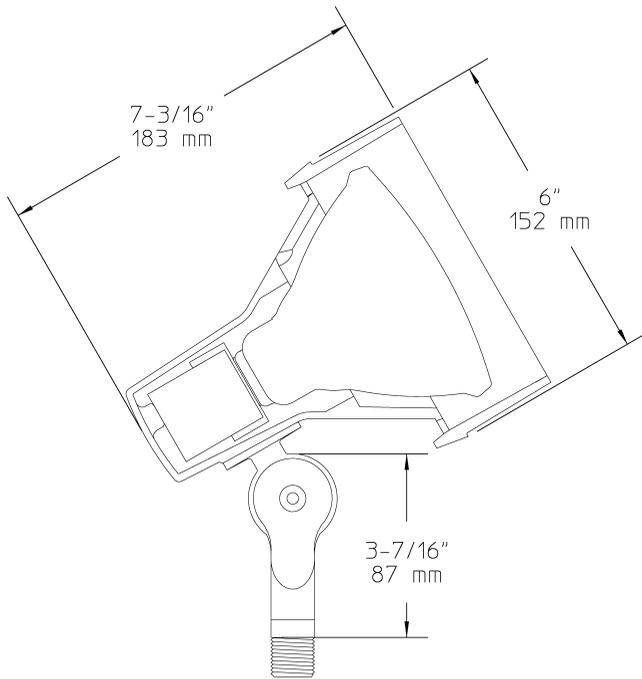

## Ordering Guide

Example: 1020 H

Product Code	1020	Aluminum Bullyte
Finish	H	Bronze

## Specifications

### HOUSING:

Die-cast aluminum. Fully-adjustable swivel arm with vibration-proof locking teeth.

### FINISH:

Thermoset polyester powdercoat is electrostatically applied after a five-stage conversion cleaning process and bonded by heat fusion thermosetting.

### LAMPING:

150W maximum PAR38/R40 incandescent lamp.

### ELECTRICAL ASSEMBLY:

4kv rated porcelain mini-can base. Nickel-plated screw shell with center contact.

### WARRANTY:

Three-year limited warranty.

### CERTIFICATIONS:

ETL listed to U.S. safety standards for wet locations. cETL listed to Canadian safety standards for wet locations. Manufactured to ISO 9001:2008 Standards.

### Width:

6" (152mm)

### Length:

7 3/16" (183mm)

### Max. Weight:

2.42 lb.