

Rana Collection
60 Inch Rana Fan MWH
310155MWH (Matte White)

Project Name: _____
Location: _____
Type: _____
Qty: _____
Comments: _____



Product Information

Product ID	310155MWH
Finish	Matte White
Blade Finish	Matte White
Collection	Rana Collection

Specifications

Number of Blades	3
Blades Included	Yes
Blade Pitch	35 Degrees
Blade Sweep	60"
Blades Reversible	No
Blade Material	ABS
Optional Blades Available	No
Downrod 1	1.00 OD X 6.00

3 Speed Wall Control Full Function - In project applications using multiple ceiling fans, alternative remote controls may be required. Please contact Kichler Advanced Product Solutions at 844-542-4537 to confirm your project requirements.


Primary Control System

Remote Included	No
Wall Control Included	Yes
Low Ceiling Adaptable	No
Lead Wire Length	78.00"
Motor Size	188MM X 20MM
Motor Type	AC INDUCTION

Downlight

Downlight Included	Yes
Light Source	LED
Downlight Bulb Included	Integrated
Downlight Bulb Type	LED
# of Bulbs/LED Modules	1
Watts	17 W
Initial Lumens	1600
Glass Description	Etched Cased Opal
Optional Light Kit Available	No
Efficacy (LMIW)	94
Kelvin Temperature	3000 K
Color Rendering Index	80

Dimensions

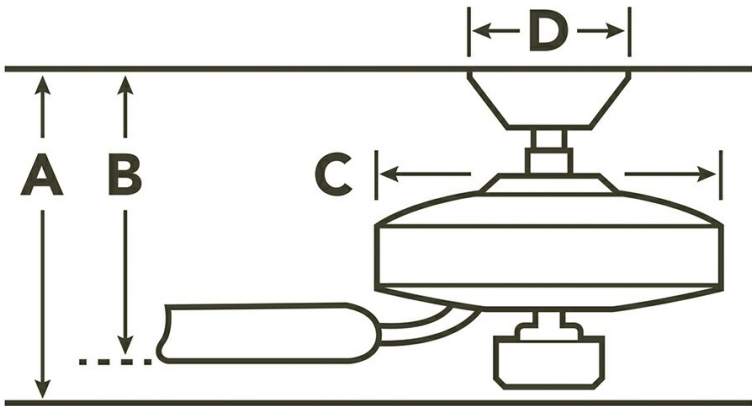

Downrod	A	B	C	D
1.00 OD X 6.00	15.75	14.50	8.75	5.75

Available Finishes

Finish	Fixture	Glass	Blade 1	Blade 2

Kichler
7711 East Pleasant Valley Road
Cleveland, Ohio 44131-8010
Toll free: 866.558.5706 or kichler.com

Notes:
1) Information provided is subject to change without notice.
All values are design or typical values when measured under laboratory conditions.
2) Incandescent Equivalent: The incandescent equivalent as presented is an approximate number and is for reference only.



Rana Collection

60 Inch Rana Fan MWH

310155MWH (Matte White)

Project Name: _____

Location: _____

Type: _____

Qty: _____

Comments: _____

Finish	Fixture	Glass	Blade 1	Blade 2
Brushed Nickel	310155NI	ETCHED CASED OPAL	NICKEL	
Matte White	310155MWH	ETCHED CASED OPAL	MATTE WHITE	
Satin Black	310155SBK	ETCHED CASED OPAL	SATIN BLACK	

Safety Listings & Certifications

Safety Rated	Wet
Energy Star	Yes
Warranty	www.kichler.com/warranty

Installation

Installation requirements	The electrical junction box and support structure must be securely mounted and capable of reliably supporting a minimum of 50 pounds. Use only ETL/UL listed electrical junction boxes marked ""For Fan Support""
Electrical Requirements	120V 60Hz AC
Hanging Weight	25.10 LBS
Minimum Distance Between Bottom Of Fan Blade To Floor	7 feet