

ACCESSORIES SECTION

2'X4', 2'X2', 1'X4' FLUORESCENT UNIVERSAL RECESSED DRYWALL FLANGE KIT




MOUNTING

Steel brackets with vertical suitability are provided to tension mount side flanges against ceiling opening. Holes provided for Chain mounting support to building structure. End flanges are pressure fit and are removable to permit for row mounting. Requires only 3" clearance over fixture depth, example: A-4" deep fixture requires only 7" cavity depth in shallower cavity applications. Fixture may be inserted into ceiling joists prior to installation of flange kit.

FEATURES

- ⌘ CONVERTS - any recessed T-bar Luminaire into a flanged recessed drywall or hardpan ceiling luminaire
 - ⌘ UNIVERSAL - fits all types of T-bar luminaires
 - ⌘ ADJUSTABLE - for drywall plaster and similar type ceilings up to 1" thick
- Press fit end flanges are removable to allow for continuous row mounting
 Requires only 3" plenum clearance over fixture depth
 Heavy duty cold rolled steel construction, die and press brace formed
 Powder coated white

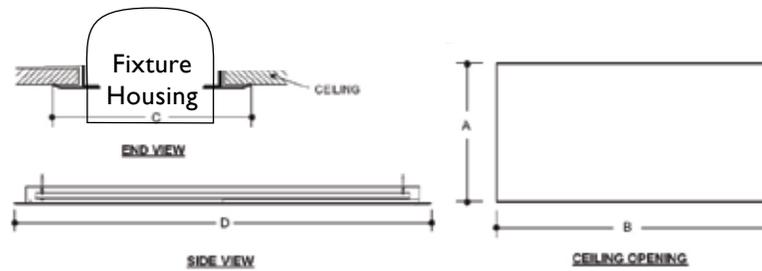

PART#	DIMENSIONS	WIDTH (A)	LENGTH (B)	WIDTH (C)	LENGTH (D)
14FK	1X4	12-3/8"	48-1/4"	13"	49"
22FK	2X2	24-3/8"	24-3/8"	25"	25"
24FK	2X4	24-1/4"	48-1/4"	25"	49"

T8/T5

FK



Fluorescent Universal Recessed Drywall Flange Kit