

# WAFER LED | SURFACE MOUNT

## 57720 / 57722 / 57724


- Die Cast Aluminum
- Size options between 4.5", 6.25" and 9"
- Ultra thin 0.5" H
- Approved for use in closets and storage spaces
- Availbale in White (WT), Bronze (BZ), and Satin Nickel (SN)
- Triac Dimmable with Electronic Low Voltage Dimmers
- Easy to install: fits in 3.25" and 4" Outlet Box
- Edge-Lit LED Technology
- Suitable for Wet Location
- ETL/cETL IP65

Job Name : \_\_\_\_\_

Job Type : \_\_\_\_\_


Quantity : \_\_\_\_\_

Comments : \_\_\_\_\_

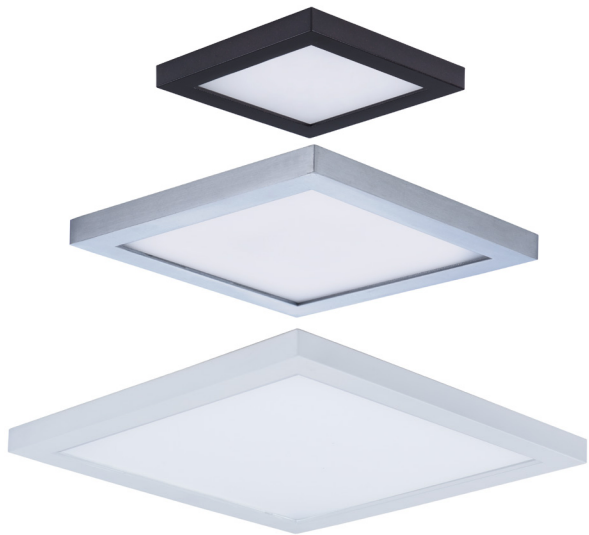

### PRODUCT DESCRIPTION

Wafer was designed for the discriminate consumer who wants the low profile look of recessed without the high cost. Manufactured of die cast aluminum, Wafer brings ultimate heat dissipation to its edge lit technology. Edge lighting gives very even light distribution while dispersing heat over a larger area. The result of this is longer LED life and better light diffusion.

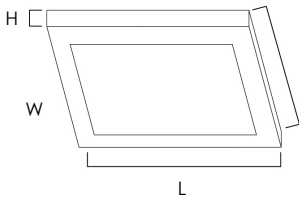

### MEASUREMENTS

#### MODEL DIMENSION

57720	4.5"L x 4.5"W x 0.5"H
57722	6.25"L x 6.25"W x 0.5"H
57724	9"L x 9"W x 0.5"H

#### HANGING WEIGHT

0.99 lb
1.21 lb
1.80 lb

### LAMPING

#### MODEL BULB TYPE

57720	10W PCB LED (Integrated)
57722	15W PCB LED (Integrated)
57724	20W PCB LED (Integrated)

CRI	LUMENS	COL TEMP.	DIMMABLE	INPUT
90+	700 600	3000K	ELV	120V
90+	1050 900	3000K	ELV	120V
90+	1400 1200	3000K	ELV	120V

### FINISHES OPTIONS:

- White (WT)
- Bronze (BZ)
- Satin Nickel (SN)



### MATERIAL:

Die Cast Aluminum  
PMMA Acrylic Diffuser

### AVAILABLE SIZES:

4.5" | 6.25" | 9"

### RATINGS:

ETL/cETL IP65  
Wet Location  
Energy Star  
CA Title 24  
ADA



### ADDITIONAL:

RATED LIFE: 50,000 Hours  
OPERATING TEMP: -20° C (-4°), 40° C (104°F)  
PHOTOMETRIC: Report Found Online

Always consult a qualified electrician before installing any lighting product



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | [maximlighting.com](http://maximlighting.com)