

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Elektron Semi-Flush Mount 3000K

| Model & Size | Color Temp & CRI | Watt | LED Lumens | Delivered Lumens | Finish |
|--------------|------------------|------|------------|------------------|---------------------|
| FM-21720 20" | 3000K 90 | 20W | 1680 | 1315 | AL Brushed Aluminum |

Example: **FM-21720-AL**

DESCRIPTION

Multiple mid-powered LED source illuminate the glass diffuser uniformly and without socket shadows common in conventional flush mounts.

FEATURES

- Uniquely versatile fixture capable of transforming before your eyes
- Side lit acrylic diffuser with discretely hidden LEDs.
- downrods can be removed to mount as a ceiling fixture or wall sconce
- Three 12" and one 6" downrods included (additional downrods available)
- Driver installed within the Junction Box, driver dimension: 2.76" x 1.26" x 1.18"
- 5 year warranty

SPECIFICATIONS

| | |
|----------------------|--|
| Color Temp: | 3000K |
| Input: | 120-277 VAC, 50/60Hz |
| CRI: | 90 |
| Dimming: | ELV: 100 - 10% |
| Rated Life: | 36000 Hours |
| Mounting: | Heavy gauge retention clips support trim firmly. Safety cabling standard., Can be mounted on ceiling or wall in all orientations |
| Standards: | ETL, cETL Damp Location Listed |
| Construction: | Aluminum hardware with etched acrylic diffuser |

REPLACEMENT PARTS

- RPL-ROD-OUT06-AL - 6" rod - AL finish
RPL-ROD-OUT12-AL - 12" rod - AL finish




FINISHES



Brushed
Aluminum

LINE DRAWING

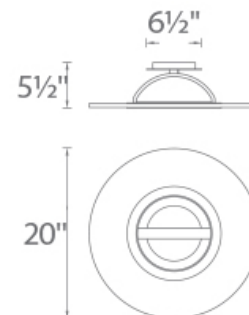

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Elektron Semi-Flush Mount 3000K

| Model & Size | Color Temp & CRI | Watt | LED Lumens | Delivered Lumens | Finish |
|--------------|------------------|------|------------|------------------|---------------------|
| FM-21728 28" | 3000K 90 | 30W | 2525 | 1720 | AL Brushed Aluminum |

Example: **FM-21728-AL**

DESCRIPTION

Multiple mid-powered LED source illuminate the glass diffuser uniformly and without socket shadows common in conventional flush mounts.

FEATURES

- Uniquely versatile fixture capable of transforming before your eyes
- Side lit acrylic diffuser with discretely hidden LEDs.
- downrods can be removed to mount as a ceiling fixture or wall sconce
- Three 12" and one 6" downrods included (additional downrods available)
- Driver installed within the Junction Box, driver dimension: 2.76" x 1.26" x 1.18"
- 5 year warranty

SPECIFICATIONS

| | |
|----------------------|--|
| Color Temp: | 3000K |
| Input: | 120-277 VAC, 50/60Hz |
| CRI: | 90 |
| Dimming: | ELV: 100 - 10% |
| Rated Life: | 36000 Hours |
| Mounting: | Heavy gauge retention clips support trim firmly. Safety cabling standard., Can be mounted on ceiling or wall in all orientations |
| Standards: | ETL, cETL Damp Location Listed |
| Construction: | Aluminum hardware with etched acrylic diffuser |

REPLACEMENT PARTS

- RPL-ROD-OUT06-AL - 6" rod - AL finish
RPL-ROD-OUT12-AL - 12" rod - AL finish



FINISHES



Brushed
Aluminum

LINE DRAWING

