

Twist-Lock® Devices
 15A, 277V AC, 2 Pole, 3 Wire Grounding
 Insulgrip® Connector

HUBBELL



Features

- Ribbed nylon housing provides secure, impact and chemical resistant grip
- Superior cord grip design protects terminations from excess strain
- Integral VARI-SIZE insert accommodates a wide range of cord diameters

Ordering Information

| Description | Cord Diameter | UPC | Catalog Number |
|------------------------|---------------------------|--------------|----------------|
| Black and white nylon. | .230"-.720" (5.8-18.3) | 783585171906 | HBL4779C |

Listings

Listed to UL 498
 Fed.Spec. W-C-596
 Certified to CSA C22.2 No.42

Specifications

| | |
|----------------------|--|
| Housing / Cord Clamp | Nylon |
| Terminal Retainer | Clear polycarbonate |
| Contacts | Brass |
| Terminal Screws | #8-32 Brass (Phillips / Slotted / Robertson) |
| Terminal Clamp | Cold rolled steel – nickel plated |
| Assembly Screws | Steel - nickel plated |

Performance

Electrical

Current Interrupting Certified for current interrupting at full rated current
 Dielectric Voltage Withstands 2,000V minimum

Mechanical

Terminal Accommodation #18 AWG- #10 AWG stranded copper wire only.




Terminal Identification Terminals identified in accordance with UL 498

Environmental

Flammability HB or better per UL94/CSA 22.2 No.0.17
 Moisture Resistance IP20 Suitability
 Operating Temperatures Maximum Continuous 75°C; Minimum -40°C (w/o impact)



15A 277V AC
 NEMA L7-15R
 UL/CSA
 2 HP

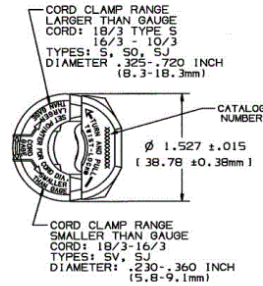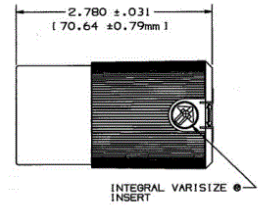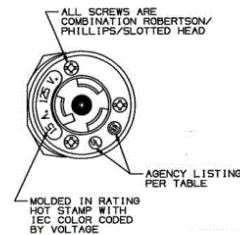

Accessories

| | |
|-------------------|----------|
| Plug | HBL4770C |
| Weatherproof Boot | HBL6024 |
| Flanged Inlet | HBL4786C |
| Weatherproof Boot | HBL6023 |

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

