

Straight Blade Devices 20A, 250V, 2 Pole, 3 Wire Grounding Insulgrip® Plug

HUBBELL



Features

- 8-Position angled plug
- Low profile
- Roomy wiring chamber provides ample space for wiring

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
8-Position Insulgrip® Angle Plug, black and white nylon	.325"-.655"(8.3-16.6)	783585174754	HBL5466CA

Listings

UL Listed to UL498 File E1706
CSA Certified to C22.2 No. 42 File 280
NEMA® WD-6 Compliant
NEMA® WD-6 Compliant

Specifications

Housing/Cord Clamp	Nylon
Blade Holder	Nylon
Terminal Retainer	Clear Polycarbonate
Blades	.060 in. (1.5) Brass
Terminal Screws	#8-32 Brass , multiple drive
Terminal Clamp	Nickel plated steel
Assembly Screws	Nickel plated steel

Performance

Electrical



Current Interrupting Certified for current interrupting at full rated current
Dielectric Voltage Withstands 2,000V minimum

Mechanical

Cord Accomodation .325"-.655"(8.3-16.6)
Terminal Accommodation #18-10 AWG. Standed copper wire only
Terminal Identification Terminals identified in accordance with UL 498 and CSA

Environmental

Flammability UL 94 HB or better
IP Suitability IP20
Operating Temperatures Maximum continuous 75°C; minimum -40°C (w/o impact)

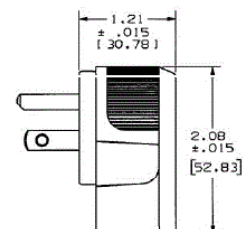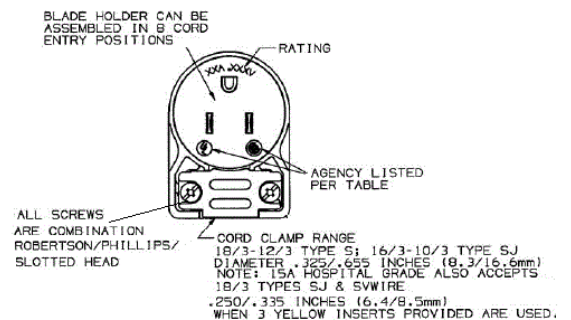

Resources

Customer Use Drawing
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

