



## ESL-LED

# ELITE LED SLIM LINK PROFILE / 120V HIGH PERFORMANCE

Among the best of lighting industry's, our dry-listed, high lumen LED Link can be the most-functional as accent, under cabinet, in display cases, for wall washing and toe kick applications in both residential and commercial environments. Complete with an integral driver, and available in variable wattages, LED Link features a full integrated diffuser to deliver glare-free even lighting, and hide the LEDs from view. Available in 6, 12, 24, 36 and 48 inches lengths, the LED Link attach together for easy installation at any desired length and uninterrupted long runs.



**50,000** hrs  
**RATED LIFE**



### Environmentally friendly

Eco-friendly design operates with no emitted infrared or ultra violet light.

### Fully integrated diffuser

Integrated diffuser is designed to conceal LED image resulting in a uniform beam of light.

### High quality construction

Made with a durable extruded aluminum housing with ribbed sides to attach mounting clips on any location.

### High quality finish

Highly durable powder-coat finish allows the fixture to integrate seamlessly into any application.

### Uniform color consistency

LEDs are binned within 4 MacAdams ellipses to ensure un-paralleled color consistency.

### Multiple assembly configurations

Includes multiple hardwire configurations such as plug-in cords, low profile bar-to-bar adapters, corner adapters, and more. Consult catalog for full list of assembly configurations.

### Dimmable down to 10% percent

Smooth and continuous dimming down to 10 percent, please consult factory for list of compatible dimmers.

### Built-in LED driver

Rated for use with existing 120V electrical systems. No additional external drivers required.


LED

ESL

ESL-LED GREAT PERFORMANCE 120V SLIM LINK PROFILE

## Product Specifications:

- :: Maximized performance, specification grade, LED strip in custom anodized housing
- :: Available in pre-cut sections allowing field assembly to every 6 or 12 inches
- :: Available in 30K and 40K CCT.
- :: Delivered up to 1125 lumens per unit
- :: Input Voltage 120
- :: Up to 58 LPW
- :: CRI: 81+
- :: Life rated at 50,000 hours
- :: Dimming compatible
- :: Engineered to eliminate 'dark zones'
- :: Built-in circuitry protects against short circuits
- :: No UV • No IR • No mercury • No lead • No Asbestos

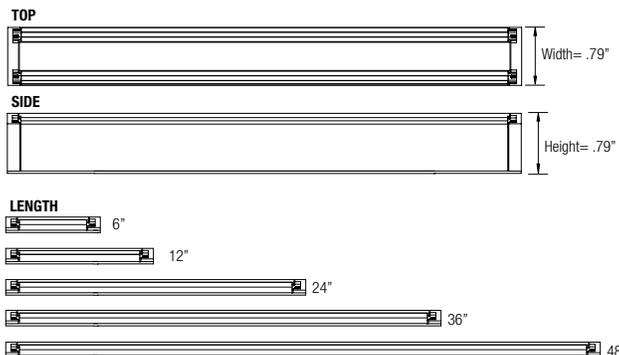

## ORDERING GUIDE

Example: **ESL-LED-6-120-30K**

TYPE	LENGTH (WATT, LUMEN)	VOLTAGE	COLOR	ACCESSORIES
ESL-LED	<input type="checkbox"/> 6" (3.1 WATT, 152 LUMEN) <input type="checkbox"/> 12" (6.1 WATT, 312 LUMEN) <input type="checkbox"/> 24" (12 WATT, 560 LUMEN) <input type="checkbox"/> 36" (16 WATT, 758 LUMEN) <input type="checkbox"/> 48" (24 WATT, 1125 LUMEN)	<input type="checkbox"/> 120	<input type="checkbox"/> 30K <input type="checkbox"/> 40K	<input type="checkbox"/> ESL-LED-ACC-1 (MOUNTING CLIPS-INCLUDED) <input type="checkbox"/> ESL-LED-ACC-2 (SHORT INTER-CONNECTOR-INCLUDED) <input type="checkbox"/> ESL-LED-ACC-3 (4" CORNER CONNECTOR FOR CONTINUOUS RUN) <input type="checkbox"/> ESL-LED-ACC-4 (MOUNTING DOUBLE-SIDED TAPE) <input type="checkbox"/> ESL-LED-ACC-5 (CONNECTION BOX) <input type="checkbox"/> ESL-LED-ACC-6 (40" POWER CONNECTOR) <input type="checkbox"/> ESL-LED-ACC-7 (40" INTER-CONNECTOR) <input type="checkbox"/> ESL-LED-ACC-8 (70" HARD WIRE CONNECTOR) <input type="checkbox"/> ESL-LED-ACC-9 (12" INTER-CONNECTOR)

### Included Accessories:

	
<b>Mounting clips</b>	<b>Short Inter-connector</b>
ESL-LED-ACC-1	ESL-LED-ACC-2

### Optional Accessories:

				
<b>4" Corner Connector for continuous runs</b>	<b>12" Inter-connector</b>	<b>40" Power Connector</b>	<b>40" Inter-connector</b>	<b>70" Hard Wire connector</b>
ESL-LED-ACC-3	ESL-LED-ACC-9	ESL-LED-ACC-6	ESL-LED-ACC-7	ESL-LED-ACC-8

	
<b>Connection Box</b>	<b>Mounting double-sided tape (Alternative)</b>
ESL-LED-ACC-5	ESL-LED-ACC-4

LED

ESL

ESL-LED GREAT PERFORMANCE 120V SLIM LINK PROFILE